


FEATURES

- **Non-Releaseable Design:** Ensures a secure and permanent hold, preventing accidental release.
- **UV Resistant:** Suitable for outdoor use, maintaining performance under sunlight exposure.
- **High Tensile Strength of 34 kg:** Offers strong holding capability for heavy-duty applications.
- **UL 94 V-2 Fire Behaviour:** Provides a level of flame retardancy, enhancing safety in fire-prone areas.
- **Maximum Bundle Diameter of 48 mm:** Accommodates a wide range of cable sizes, offering versatility.
- **Operating Temperature up to 85 °C:** Suitable for use in high-temperature environments.
- **4.6 mm Width:** Balances flexibility and strength, ensuring ease of use and durability.

RS PRO 200mm Nylon Cable Tie, Non-Releaseable

RS Stock No: 656-056

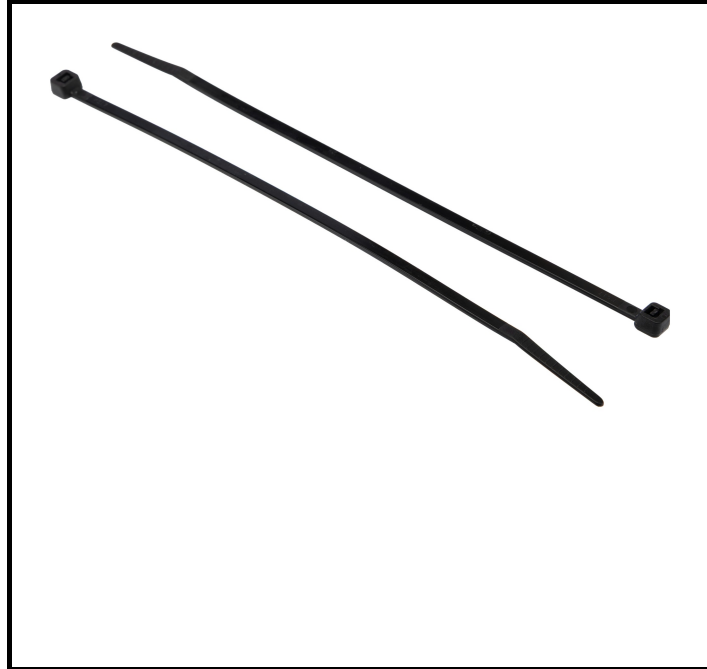

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

These RS PRO cable ties are designed for securing and organising cables efficiently. Made from durable nylon, they are ideal for bundling cables in various environments, providing a reliable and robust solution for cable management.

General Specifications

Colour	Black
Product Type	Cable Tie
Sub Type	Non-Releaseable
Tensile Strength	34 kg

Protection Category

Fire Behaviour	UL 94 V-2
UV Resistant	Yes

Mechanical Specifications

Length	200 mm
Material	Nylon
Maximum Bundle Diameter	48 mm
Width	4.6 mm

Operation Environment Specifications

Maximum Operating Temperature	85 °C
-------------------------------	-------

Approvals

Standards/Approvals	ABS 15-TA1338482-PDA, cULus E97527, RoHS, UL94V-2
---------------------	---

