


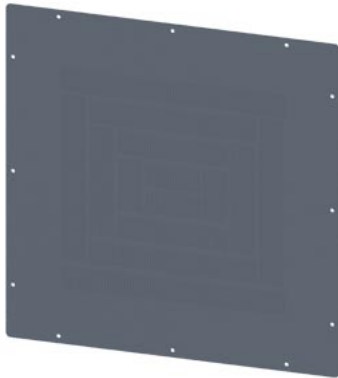

SIVACON, Roof, with Ventilation openings with Ventilation openings IP40, W: 600 mm, T: 600 mm, zinc-plated

Model		
product brand name	SIVACON	
product designation	top plate	
design of the product	With ventilation openings	
design of the surface	zinc plated	
design of the product EMC version	No	
Protection class		
protection class IP	IP40	
Suitability		
suitability for use for outside use	No	
Product details		
product component		
• cable entry	No	
• ventilation	Yes	
Mechanical Design		
width	600 mm	
depth	600 mm	
ventilation cross section outlet can be used	380 cm²	
net weight	4.6 kg	
material	steel	
Approvals Certificates		
General Product Approval	Test Certificates	other



[Special Test Certificate](#)

[Confirmation](#)

[Miscellaneous](#)

other

Environment

[Miscellaneous](#)

Siemens
EcoTech



[Environmental Confirmations](#)

Further information

Information on the packaging

<https://support.industry.siemens.com/cs/ww/en/view/109813875>

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1066-2UD30-0A>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/en/ps/8MF1066-2UD30-0A>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1066-2UD30-0A

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

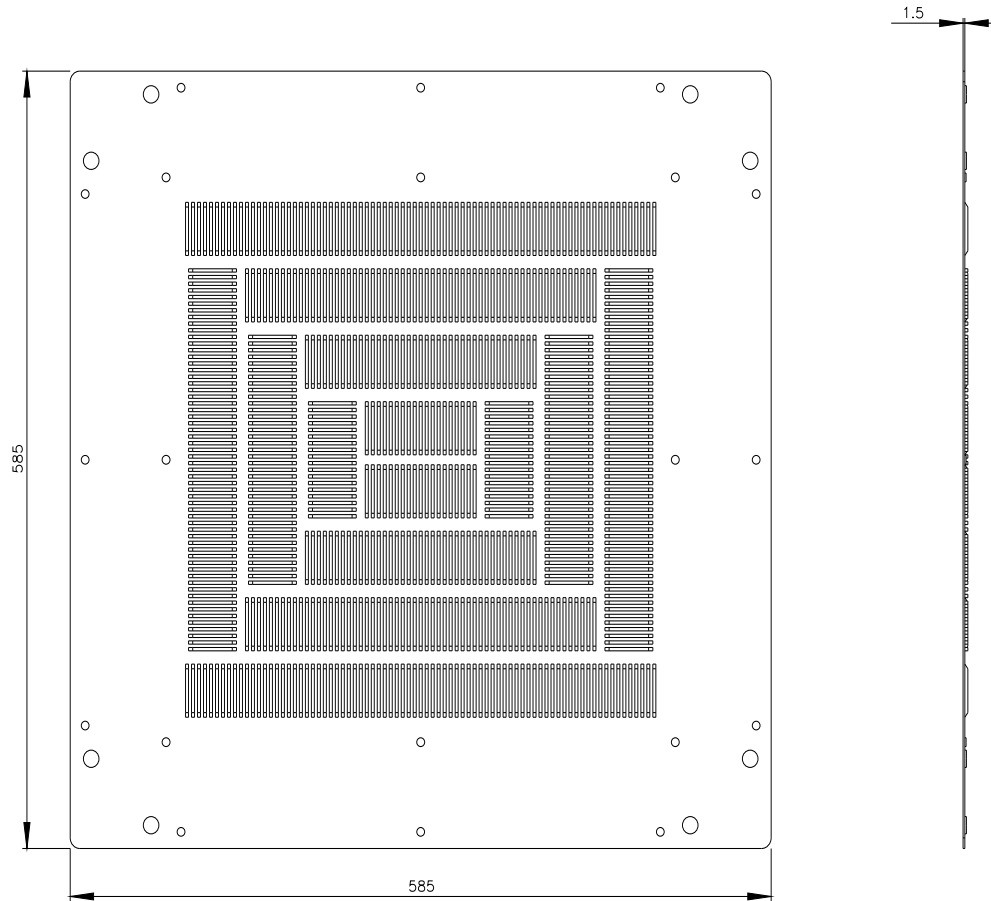

last modified:

1/16/2025 

