


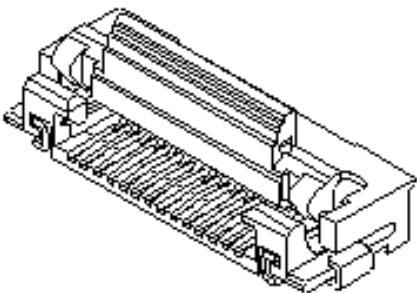


**Part Number :** [528920896](#)  
**Product Description :** 0.50mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, Cable Retention Guide, 8 Circuits, Gold (Au) Contact Plating  
**Series Number :** 52892  
**Status :** Obsolete  
**Product Category :** FFC / FPC Connectors



## Documents & Resources

## Product Environment Compliance

### Compliance

GADSL/IMDS	Compliant with Exemption 44; 33
China RoHS	
EU ELV	Not Relevant
Low-Halogen Status	Not Low-Halogen per IEC 61249-2-21
REACH SVHC	Not Contained per D(2024)6225-DC (07 Nov 2024)
EU RoHS	Compliant per EU 2015/863

### Multiple Part Product Compliance Statements

- Eu RoHS
- REACH SVHC
- Low-Halogen

### Multiple Part Industry Compliance Documents

- IPC 1752A Class C
- IPC 1752A Class D
- Molex Product Compliance Declaration
- IEC-62474
- chemSHERPA (xml)

### EU RoHS Certificate of Compliance

## Part Details

## General

Status	Obsolete
Category	FFC / FPC Connectors
Series	52892
Description	0.50mm Pitch Easy-On FFC/FPC Connector, Right-Angle, Surface Mount, ZIF, Bottom Contact Style, Cable Retention Guide, 8 Circuits, Gold (Au) Contact Plating
Comments	Hinge, Cable Guide
Product Name	Easy-On
UPC	883906525682

## Electrical

Current - Maximum per Contact	0.5A
Voltage - Maximum	50V

## Physical

Actuator Type	Front Flip
Circuits (Loaded)	8
Contact Position	Bottom
Durability (mating cycles max)	20
Mated Height	2.00mm
Material - Metal	Phosphor Bronze
Material - Plating Mating	Gold
Material - Plating Termination	Gold
Net Weight	121.000/mg
Orientation	Right Angle
Packaging Type	Embossed Tape on Reel
PCB Locator	No
PCB Mounting	Surface Mount
PCB Retention	Yes
Pitch - Mating Interface	0.50mm
Polarized to PCB	No
Stackable	No
Temperature Range - Operating	-30° to +85°C

Wire/Cable Type	FFC/FPC
-----------------	---------

This document was generated on Mar 27, 2025