


440 - METRIC COMBINATION WRENCHES | 440.4H

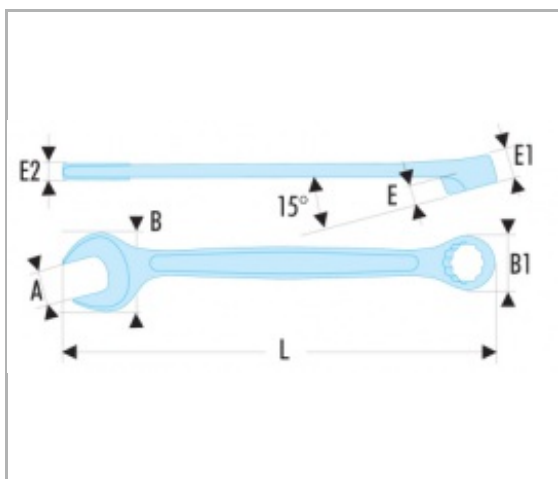

Norm :

NF ISO 691, NF ISO 7738, NF ISO 3318, NF ISO 1711-1, E74-306, ISO 691, ISO 7738, ISO 3318, ISO 1711-1, DIN ISO 691, DIN 1711-1, DIN 3113, ASME B107.100

Description

- Standard wrench for all current applications.
- High mechanical strength combined with compact size meeting aeronautical standards.
- Ring head:
 - Ring open end (size E) designed for better access to series or embedded screws.
 - OGV® profile with 12-point ring for powerful tightening while protecting the nut. H suffix = 6-point ring.
 - Ring head angled at 15°.
- Open end head:
 - Open end angled at 15°.
 - Open end head-handle geometry optimised for increased access.
- Metric sizes: 4 to 41 mm.
- Presentation: satin chrome finish.

Information

A [mm]	4
B [mm]	10,0
B1 [mm]	7,8
C1 [mm]	3,5
E [mm]	2,1
E1 [mm]	3,5
E2 [mm]	3,0
L [mm]	106
[g]	10

