 



# suction cup ESS-8-SU

Part number: 189280

FESTO

Wearing part, easily replaceable

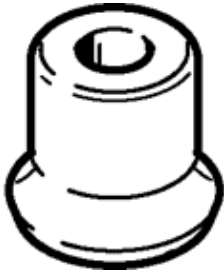

## Data sheet

Feature	Value
Min. workpiece radius	20 mm
Nominal size	2 mm
suction cup diameter	8 mm
suction cup volume	0.03 cm <sup>3</sup>
Ejector pulse suitability	≤ 4 bar
Position of connection	on top
Assembly position	Any
Correlation to suction-cup holder	Size 2
Suction cup shape	round flat
Operating pressure	0 ... 0.95 bar
Nominal operating pressure	-0.7 bar
Operating medium	Atmospheric air based on ISO 8573-1:2010 [7:::]
Corrosion resistance classification CRC	1 - Low corrosion stress
Food-safe	See Supplementary material information
Ambient temperature	-20 ... 60 °C
Retention force at nominal operating pressure	2.3 N
Lateral force at nominal operating pressure	5 N
Product weight	0.2 g
Mounting type	Via vacuum port
Vacuum connection	Inside diameter 4 mm
Colour	blue
Shore hardness	60 +/- 5
Material of threaded plug	Nickel-plated brass
Materials note	Free of copper and PTFE Contains PWIS substances Conforms to RoHS
Material suction cup	PUR