



red dot winner 2022
best of the best

CCG 18-125 BLPD SEC PROTAGO

The new FEIN cordless angle grinder

A unique operating concept that almost fully eliminates the risks associated with improper operation.
FEIN – one less thing to worry about.

APPLICATIONS

- + Cutting of sheet metal , profiles , pipes and solid material
- + Deburring
- + Grinding work
- + Surface machining

TARGET GROUPS

- + Steel and metal construction / locksmith's shops
- + Boiler, container and tank construction
- + Mechanical Engineering
- + Industrial steel construction
- + Industry
- + Aerospace




FEIN ADVANTAGES

PROTAGO. SIMPLY SAFE-SAFE.

- + Two-handed operation provided by integrated dead man's switch ("AutoStop") and permanently fitted additional handle
- + Safe guidance thanks to the additional handle, which can be adjusted into 6 positions
- + Kick-back monitoring, soft start, restart protection, electronic overload protection
- + Non-removable safety hood, tool-free adjustable.
- + Fully enclosed motor housing protects the motor from aggressive ceramic and mineral dusts
- + Tool-free quick clamping system
- + Infinitely variable electronic speed preselection
- + Fatigue-free working thanks to narrow grip dimensions, compact design and a well-balanced low weight

Technical data		CCG 18-125 BLPD SEC
Battery voltage	V	18
Battery compatibility		Li-Ionen / HighPower Li-Ionen
Battery interface		Multi-Volt
Speed, no load	1/min	2500 - 8.500
Grinding disc	mm	125
Elastic backing pad	mm	125
Weight without battery	kg	2,3
Material number (N00)		7 120 08 61 00 0
Scope of delivery	2 HighPower Akku-Pack 5,2 Ah, 1 quick charger ALG 80 BC, 1 quick-clamping nut, 1 cover for cutting work, 1 bidirectional nut spanner, 1 tool case	

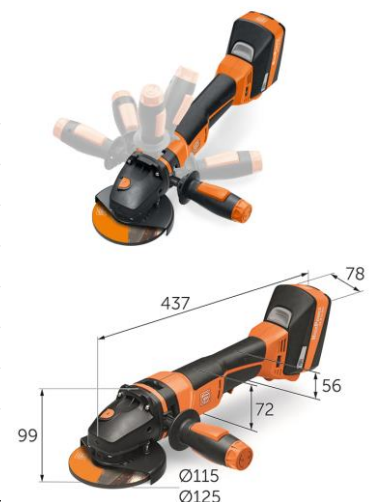

All rights reserved by FEIN. In particular in the event of an application for industrial property rights. All rights of disposal, such as copying and distribution, are reserved by FEIN.