

Technical data


WS81117

Thrust washer



Needle roller bearing, thrust needle roller bearing, inner ring

VISUAL (S)

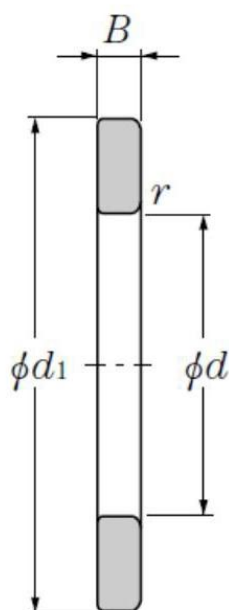

PRODUCT DEFINITION

Brand	NTN
d - Bore diameter of support washer IR - WS	85 mm
d1 - External diameter of support washer IR - WS	110 mm
B - Ring thickness	5,75 mm
rs - Min fillet radius	1 mm
Bearing ring (inner ring) WS mass	0,175 kg

PRODUCT PERFORMANCE

Tmin - Min operating temperature	253,15 °K
----------------------------------	-----------



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT PERFORMANCE

Tmax - Max operating temperature	393,15 °K
----------------------------------	-----------

