

DYMO®



LabelManager™ 280



CREATE LABELS FAST WITH SMART KEYS

Customize labels using the PC or MAC® connectivity to import your own fonts and graphics

Features

- Large LCD display
- Computer-style keyboard
- One-touch Smart Keys for fast formatting
- Long lasting rechargeable battery pack
- 20+ ways to format text
- 200+ symbols and clip-art images
- Print up to 1/2 in (12 mm) wide labels
- For even more features, download DYMO® Connect for Desktop Software



Single Unit Includes:

- LabelManager 280
- Rechargeable Lithium-Ion Battery
- D1 Starter Label Cassette, 12mm x 3m Black on White
- USB Cable
- Charging Adapter
- Quick Start Guide
- 2 + 1 - Year Limited Warranty*



Kit Includes:

- LabelManager 280 + Softcase Bag
- Rechargeable Lithium-Ion Battery
- 2x D1 Label Cassette, 9mm x 7m Black on Clear | 12mm x 7m Black on White
- USB Cable
- Charging Adapter
- Quick Start Guide
- 2 + 1 - Year Limited Warranty*



Quick Specs

Unit Dimensions (H x W x L)	107.5 x 206 x 46.5 mm
Weight (excluding battery)	810 g
Mac®/PC Compatible	Yes via DYMO® Connect for Desktop Software
Accepts Label Sizes	6mm, 9mm and 12mm
Tape Platform	D1, Durables
Resolution	180 dpi
Printing System	Thermal Transfer
Print Speed	15 mm/sec
Barcodes	Yes via DYMO® Connect for Desktop Software
Cutter Type	Manual
Batteries	Rechargeable
AC Adapter	Yes (included)
Networking	No
Country of Origin	China

Item Number	Description		Length (cm)	Width (cm)	Height (cm)	QTY	EAN	Customer Price
7753925	LabelManager 280 QWERTY UK	Unit	8.9	19.0	24.0	1	3501170968963	
Contact your RS Components team for availability.	LabelManager 280 QWERTY KIT	Unit	20.5	10.2	5.7	1	3026980911522	
Accessories (www.dymo.com)								
Contact your RS Components team for availability.	Charging Adapter	Unit	9.0	4.8	8.2	1	-	

* +1 year if registered on the Dymo website



D1 Standard Polyester Labels

For hundreds of tasks around the office or home office, such as filing, storage and asset tracking.
Temperature rating: -18°C to 90°C


D1 STANDARD LABELS (3 m)	6 mm	9 mm	12 mm
ABC	Contact your RS Components team for availability.		
ABC	Contact your RS Components team for availability.		
D1 STANDARD LABELS (7 m)	6 mm	9 mm	12 mm
ABC	2086668	2030457	497432
ABC	2086630	2030441	497410
ABC	2086652	2030485	497476
ABC	-	2170202	494641
ABC	-	2170218	494657
ABC	-	2030479	497460
ABC	-	-	2170189
ABC	-	2170195	497448
ABC	-	-	494635
ABC	-	-	2172343
ABC	-	2030463	497454
ABC	-	-	497426
D1 STANDARD MULTIPACKS (7 m)	6 mm	9 mm	12 mm
ABC	-	1920480	1920481



D1 Durable Vinyl Labels

Industrial strength adhesive helps to ensure labels stay stuck to a variety of surfaces.
Temperature rating: -40°C to 80°C

D1 DURABLE LABELS (3 m)	12 mm
ABC	1245866
ABC	1245865
ABC	1245867
D1 DURABLE LABELS (5.5 m)	12 mm
ABC	1245864

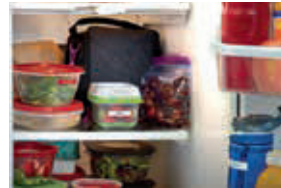

D1 Permanent Polyester Labels

Professional, polished finish ideal for panels, blocks, faceplates, shelves, bins and more.
Temperature rating: -40°C to 150°C*

D1 PERMANENT POLYESTER (5.5 m)	12 mm
ABC	4493945

*depends on surface



D1 Flexible Nylon Labels

Specifically designed for curved surfaces and wire and cable marking.
Temperature rating: -40°C to 60°C

D1 FLEXIBLE NYLON (3.5 m)	12 mm
ABC	4493658



The DYMO® high quality labels are made in Belgium

