



Brand of NTN corporation


Technical data

BB8UU

Standard ball bushings closed



VISUAL (S)

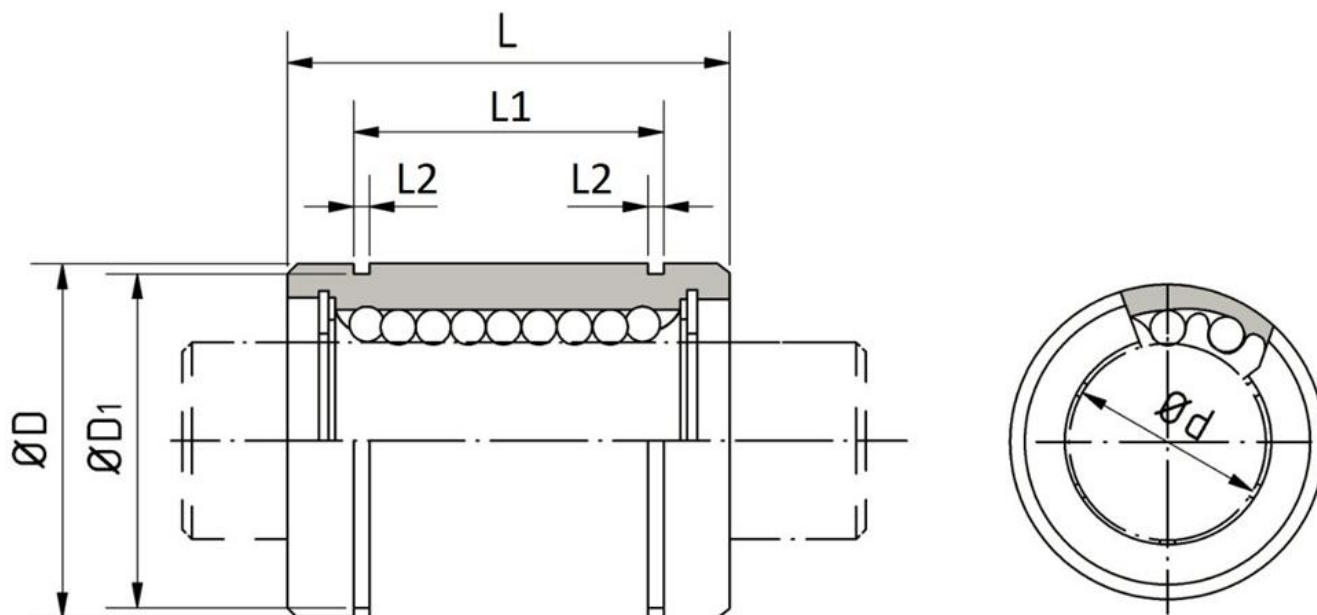

PRODUCT DEFINITION

Brand	SNR
Design type	BBE
Ball bushings category	Standard ball bushings, closed
Standard	JIS dimension
Number of seals	2
Material outer cylinder or steel segments	100Cr6
Material Cage	PA
Initial greasing	Non/No
d - Internal diameter	8 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

PRODUCT DEFINITION	
d - Internal diameter tolerance	0/-0,009
D - External diameter	15 mm
D - External diameter tolerance	0/-0,011
L - Length	24 mm
L - Length tolerance	0/-0,2
L1	17,5 mm
L1 tolerance	0/-0,2
D1 - Diameter	14,3 mm
L2	1,1 mm
Number of ball rows	4
Mass	0,017 kg

PRODUCT PERFORMANCE	
Cmin	0,194 kN
Cmax	0,274 kN
C0min	0,392 kN
C0max	0,554 kN
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	80 °C

ESHOPDONOTDISPLAY	
Reference	BB8UU
Image	BBE+BB_1.JPG, BBE+BB_3.JPG
Send to Eshop	Yes
Send to Paper Catalog	Yes



ESHOPDONOTDISPLAY

Tracepart

Oui/Yes

