



Application Tooling > Hand Crimping Tools



Tool Grade: **Commercial Crimp Tooling**  
Ratchet Configuration: **Operator Releasable & Adjustable**  
Die Sets Type: **Removable/Interchangeable**  
Specification Type: **TE Product Specification (114-)**  
TE Certification: **Upon Request for Fee**

Features

Other

|                             |                                     |
|-----------------------------|-------------------------------------|
| Crimp Form-Wire Barrel Type | Open Barrel - F Crimp               |
| Tool Grade                  | Commercial Crimp Tooling            |
| Ratchet Configuration       | Operator Releasable & Adjustable    |
| Die Sets Type               | Removable/Interchangeable           |
| Specification Type          | TE Product Specification (114-)     |
| TE Certification            | Upon Request for Fee                |
| Power Technology Type       | Manual                              |
| Tooling Type                | Ergocrimp Hand Tool Assembly or Die |

Product Compliance

[For compliance documentation, visit the product page on TE.com>](#)

|                                               |                                                                                                                                |
|-----------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------|
| EU RoHS Directive 2011/65/EU                  | Compliant                                                                                                                      |
| EU ELV Directive 2000/53/EC                   | Compliant                                                                                                                      |
| China RoHS 2 Directive MIIT Order No 32, 2016 | No Restricted Materials Above Threshold                                                                                        |
| EU REACH Regulation (EC) No. 1907/2006        | Current ECHA Candidate List: JAN 2025 (247)<br>Candidate List Declared Against: JUNE 2024 (241)<br>Does not contain REACH SVHC |
| Halogen Content                               | Low Halogen - Br, Cl, F, I < 900 ppm per                                                                                       |



homogenous material. Also BFR/CFR/PVC  
Free

Solder Process Capability

Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) ‘Guidance on requirements for substances in articles’ posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>

Compatible Parts



TE Part # 5-1105250-1  
HSM-C-Sti.Ag.6 qmm



TE Part # 4-1108757-1  
HSK.Sti.C.6,0 qmm



TE Part # 4-1105250-1  
HSM-C-Sti.Ag.4 qmm



TE Part # 4-1105151-1  
HSS-C-Bu.Ag.10,0 qmm



TE Part # 2-1105150-1  
HSS-C-Sti.Ag.4,0 qmm



TE Part # 4-1105150-2  
HSS-C-Sti.Au.10,0 qmm



TE Part # 4-1105150-1  
HSS-C-Sti.Ag.10,0 qmm






TE Part # 3-1108757-1  
HSK.Sti.C.4,0 qmm



TE Part # 2-1105151-1  
HSS-C-Bu.Ag.4,0 qmm

Customers Also Bought

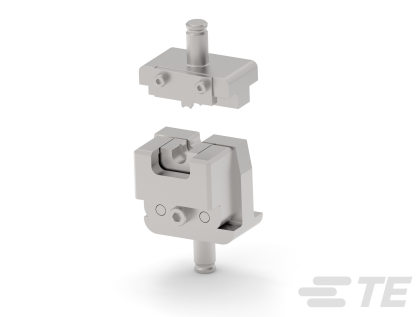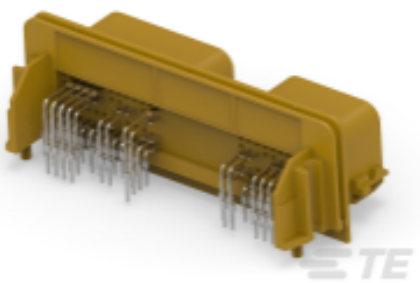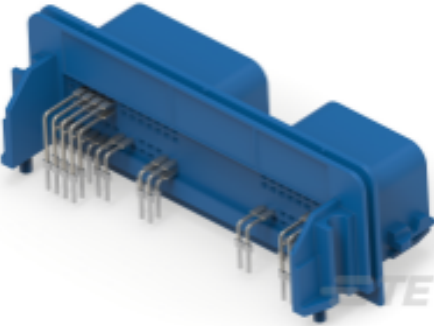

|                                                                                                                                                  |                                                                                                                                                  |                                                               |                                                                                                                                                 |
|--------------------------------------------------------------------------------------------------------------------------------------------------|--------------------------------------------------------------------------------------------------------------------------------------------------|---------------------------------------------------------------|-------------------------------------------------------------------------------------------------------------------------------------------------|
|  <p>TE Part #2234179-1<br/>DIE SET DIA 6MM T 4-6MM2</p>         | <p>TE Part #7-2324277-2<br/>ACU 66P HDR ASSY(A2A4-B4B10)</p>                                                                                     | <p>TE Part #2354815-1<br/>ACU SLD 66P HDR ASSY(A4A7-B1B7)</p> | <p>TE Part #2326501-3<br/>NEST HVM HEX</p>                                                                                                      |
| <p>TE Part #2326297-5<br/>INDENTER HVM WM</p>                                                                                                    | <p>TE Part #5-2351799-3<br/>ACU 88P HDR ASSY(A1A5-B6B9)</p>                                                                                      | <p>TE Part #3-2351799-9<br/>ACU 88P HDR ASSY(A1A3-B8B9)</p>   |  <p>TE Part #2-2351799-3<br/>ACU 88P HDR ASSY(A1A3-B6B8)</p> |
|  <p>TE Part #1-2351799-7<br/>ACU 88P HDR ASSY(A2A4-B6B10)</p> |  <p>TE Part #1-2351799-5<br/>ACU 88P HDR ASSY(A1A5-B5B10)</p> |                                                               |                                                                                                                                                 |

Documents

Product Drawings  
RSZ.LC.4-10QMM

German

Datasheets & Catalog Pages  
1-1773865-2\_1015\_Commercial Manual Hand Tools

English

Bottoming Dies  
English