



# Datasheet

ENGLISH

## **RS Unshielded Test Lead Wire 2.5 mm<sup>2</sup> CSA 500 V Black Silicone Rubber Single Core, 462 Strands 5m**

RS Stock number 748-1998



**Product Code:** Silicone test lead wire 2.5mm<sup>2</sup>

### **Product Description**

#### **Reference Standard**

Customer's sample spec. and the general standard

#### **Multi-construction**

Single

### **Cable Construction**

#### **Conductor**

Cross section

Construction(±0.003mm)

Standard Dia.

#### **Jacket**

Thickness

Jacket Dia.(mm)

Color

#### **Tinned Copper**

2.5mm<sup>2</sup>

T0.08× 462

1.98

#### **silicone rubber**

0.95

3.90±0.15

Red: Black;

Blue; Yellow

Green


#### **Marking**

No Printing

#### **PACKAGING**

5M/ plastic Bag

Suitable pieces/Box

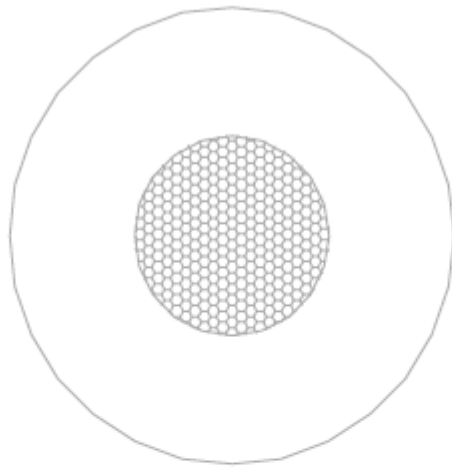

**Electrical Characteristics**

Max.Conductor DC Resistance at 20 °C ( Ω /Km)	8.02
Min.Insulation DC Resistance at 20 °C (MΩ *Km)	>500
Rated Temperature(°C)	-55~+200
Rated Voltage (V)	300/500