



TECHNICAL SPECIFICATIONS

- Phosphated steel sheet, thickness **6/10**, **8/10** for the body and **8/10ths** for the doors
- A high welded shelf
- Vertical divider under the shelf separating work linen and civilian linen
- Top and bottom ventilation holes, omega reinforcement inside each door

- Padlock door lock
- Hanger bar with 2 hooks
- Each cubicle is equipped a small vanity mirror and a coat hook.
- 1 label holder on each door


Without feet :

Reference	Version	W x D x H
CVS411DSP	1 box	400 x 500 x 1800
CVS412DSP	2 boxes	800 x 500 x 1800
CVS413DSP	3 boxes	1200 x 500 x 1800

With feet :

Reference	Version	W x D x H
CVS411DAP	1 box	400 x 500 x 1940
CVS412DAP	2 boxes	800 x 500 x 1940
CVS413DAP	3 boxes	1200 x 500 x 1940

OPTIONS AND ACCESSORIES

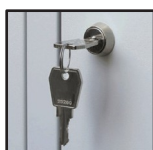

Key lock



Code lock with key decoding




COSERELEC electronic lock



3-wheel round code lock



Coin-operated lock €1

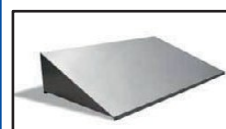

Slanted caps
Mandatory in the food industry, they ensure better hygiene conditions.



Bench bases Legs
in 25 x 25 mm tube with adjustment jacks

STANDARD COLOURS

