



### Main

Accessory / separate part category	Cabling accessory
Accessory / separate part type	Pre-wired connectors
Series name	Application

### Complementary

Electrical connection	M12, 4 pins straight female connector
Cable connector fixing	Screw-on
Collar material	Stainless steel 316L
Status LED	Without
Cable length	10 m
Cable outer diameter	5.3 mm
Cable composition	4 x 0.34 mm <sup>2</sup>
Wire insulation material	PVC
[Ue] rated operational voltage	250 V AC 300 V DC
[In] rated current	4 A
Contact resistance	5000 µOhm
Insulating resistance	1 GΩ
Product weight	0.37 kg

### Environment

IP degree of protection	IP69K
Ambient air temperature for operation	-25...85 °C (static)
Ambient air temperature for storage	-35...100 °C

### Offer Sustainability

RoHS (date code: YYWW)	Compliant - since 0601 - Schneider Electric declaration of conformity <a href="#">Schneider Electric declaration of conformity</a>
------------------------	---

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications


Contractual warranty

---

Warranty period	18 months
-----------------	-----------

---

Dimensions

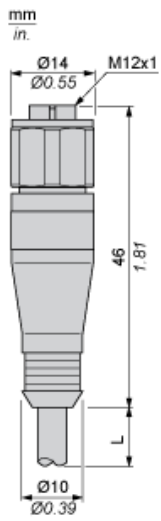


L : Length of cable

---

Connections and Schemes

---

Connector

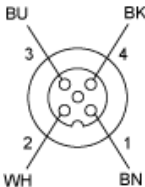

- BN : Brown
- BK : Black
- BU : Blue
- WH : White