


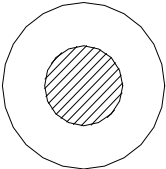

Datasheet

Product Name:	UL1213 24AWG
Product Discription:	UL1213 24AWG
Specification No.:	
Customer's Name:	

Description		Construction			
Rated Voltage:	Not specified	Conductor	Stranded Sliver plated copper		
Rated Temperature:	105°C, 60 °C Oil	Size(AWG)	24		
Reference Standard:	UL758	Construction(±0.008mm)	7/0.203		
Cross Section 		Stranded Dia.(mm)Ref.	0.61		
		Insulation Material	PTFE		
		Insulation Color	ANY COLOR		
		Ave Thickness(mm)	0.2		
		Insulation Dia.(±0.08mm)	1.09		

Marking	
No marking on the cable jacket, have UL label on the Reel.	

Remark:	8739696 Grey	8739692 Orange
	8739699 Yellow	8739706 Violet
	8739680 Brown	

Applications		Characteristics		Customer Approve
Internal wiring where not subjected to mechanical abuse, Oil Resistant 60 deg C.		Test Item	Standard Value	Seal & Stamp
		Test Material	PTFE(ROHS)	
		Insulation resistance(20°C MΩ*m)	1000	
		Vol. Tesr(AC.V.60S) (V)	2000	
		Flammability Test	Horizontal flame	
		Max.DC Resistance(20°C Ω/km)	78.4(MAX)	

Revisions				
Version	Description	Drawn by	Approved by	Date
0	New document issue	Danniel	Jason	24/04/2015

Signature:
Date: