



Single row shrouded headers

INTERCOM

FEATURES

Pitch 2.54 mm
Conforms to HE13, HE14,
IEC 603-8.

TECHNICAL DATA

Material
Housing: Black thermoplastic
GF UL94 V0
High temperature
Contact: phosphor bronze.

Electrical

Current rating: 4 A maxi.
Voltage: 1000 V eff.
Insulation resistance:
1x10⁴ MΩ mini

Mechanical

Temperature rating:
-55°C to +125°C
Pc board Hole diameter Ø 1 mm.


PACKAGING

Recyclable cardboard boxes

Mates with the following
connectors:

4782863; 4782709; 4782837;
4782710; 4783219; 4853248.


High Temperature

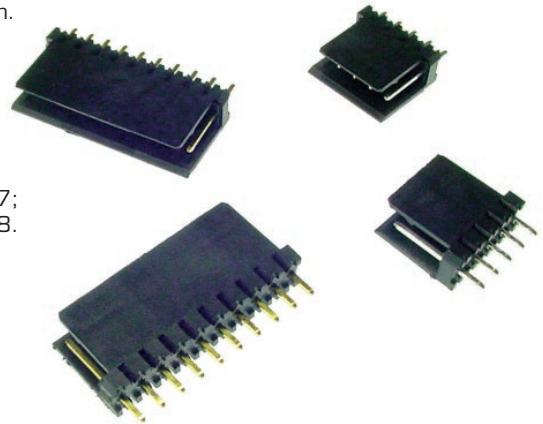

a	b	c	d	e	
475	0334	1	xx	4x0	- 1

d Number of contacts
from 02 to 20.

e Plating
0 Gold
0.2 µm over Ni 1.27 µm
4 Tin 4 µm over Ni 1.27 µm
7 Selective Gold
0.2 µm over Ni 1.27 µm
Other platings on demand.

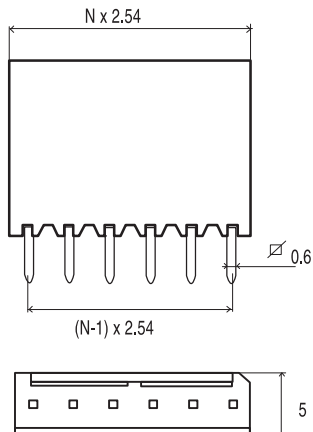

For alternative products
see also page 130.