



PBS35-XL

Plummer block housing unit

Plummer block housing units PBS, sheet steel housing, radial insert ball bearing with eccentric locking collar, P seals

X-life

Technical information

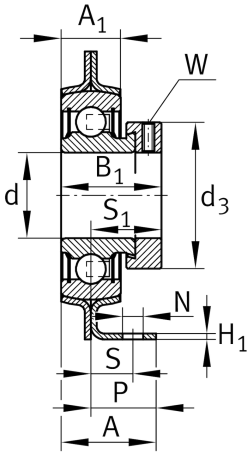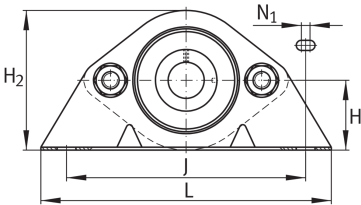

Your current product variant

Material Steel sheet

Main Dimensions & Performance Data

d	35 mm	Bore diameter
H 2	94.4 mm	Height
L	165 mm	Length total
C 0r G	4,100 N	Load carrying capacity (housing)
≈m	1.01 kg	Weight

Mounting dimensions

J	127 mm	Distance fixing bore
N	13.5 mm	Width (slot)
N 1	8 mm	Distance slot center
S	20.7 mm	Distance fixing

Dimensions

H	47.6 mm	Distance shaft axis
A	46.1 mm	Width (base)
A 1	22.2 mm	Width (head)
H 1	4 mm	Heigth (base)
P	35 mm	Distance support



Additional information

GEH72-PBS	Housing
RAE35-XL-NPP-B	Bearing designation

Temperature range

T _{min}	-20 °C	Operating temperature min.
T _{max}	120 °C	Operating temperature max.