

 


AN00, Silencer, Standard AN700-12

Datasheet

General series information

- Fluid: compressed air
- Noise reduction: 25-35 dB(A) or more
- Maximum operating pressure: 1.0MPa
- Effective area mm² (Cv): AN*00 35-960 (1.9-53); AN*02 35-90 (1.9-5.0); AN*03 10-60 (0.6-3.3)
- Ambient & fluid temperature: 5 - 60° C






Silencer

Standard specifications

Model	AN700-12 (Size 7-Standard, Noise Reduction-Standard (30 dB), Port Size 1 1/4)
Pressure medium	Compressed Air
Maximum operating pressure	1.0 MPa
Maximum ambient temperature	60 °C
Minimum ambient temperature	5 °C
Noise reduction	25-35 dB
Effective Area	440 mm ²
Weight	0.490 Kg

Dimensions

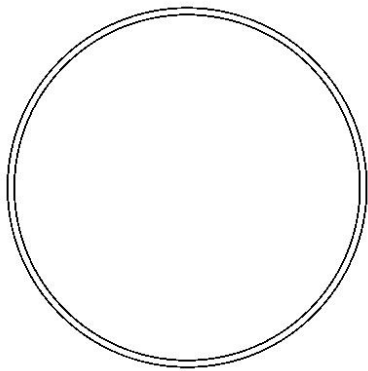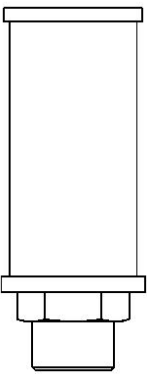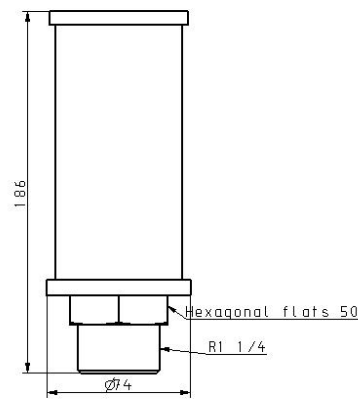

Additional information

Catalogue

[AN_EU.pdf](#)