

Electronics cases – Interscale M

Desktop cases




- Modular desktop case consisting of 4 assembled parts
- Case available in two versions: Plain or perforated for forced cooling with fans
- Ingress protection IP 30 (plain version)
- Color RAL 7016

NEW

Delivery includes (assembled)

Item	Qty	Description
1	1	Base with 2 side panels (plain or perforated), St, 1 mm, AlZn coated, RAL 7016 (anthracite gray)
2	1	Top cover, St, 1 mm, AlZn coated, RAL 7016
3	1	Front panel, Al, 1 mm, RAL 7016
4	1	Rear panel, Al, 1 mm, RAL 7016
5	1	Assembly kit and user manual

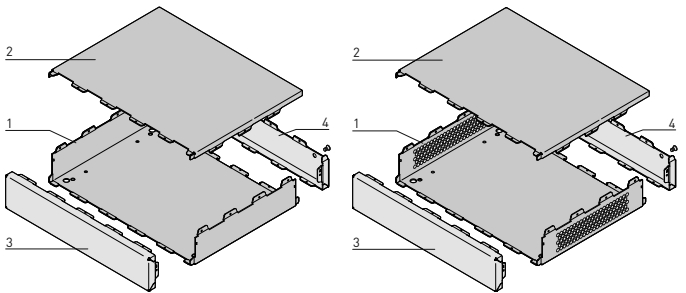

Plain case

Perforated case



ServicePLUS

Order Information

Height	Width	Depth	Desktop case plain	Desktop case, perforated			Mounting plate	PCB support for mounting plate	
			Desktop case plain	Desktop case perforated	Mounting plate with built-in fan	Fan holder with fans			
U	mm	mm	mm	Part no.	Part no.	Part no.	Part no.	Part no.	
1	44	133	133	14820-133	–	–	–	24822-033	24827-023
1	44	133	177	14820-134	–	–	–	24822-034	24827-024
1	44	221	177	14820-154	14825-154	24827-154	24828-104	24822-054	24827-024
1	44	221	221	14820-155	14825-155	24827-155	24828-105	24822-055	24827-025
1	44	310	221	14820-175	14825-175	24827-175	24828-105	24822-075	24827-025
1	44	399	221	14820-195	14825-195	24827-195	24828-105	24822-095	24827-025
1	44	399	310	14820-197	14825-197	24827-197	24828-107	24822-097	24827-027
2	88	221	177	14820-254	14825-254	24827-254	24828-204	24822-054	24827-024
2	88	221	221	14820-255	14825-255	24827-255	24828-205	24822-055	24827-025
2	88	310	221	14820-275	14825-275	24827-275	24828-205	24822-075	24827-025
2	88	399	221	14820-295	14825-295	24827-295	24828-205	24822-095	24827-025
2	88	399	310	14820-297	14825-297	24827-297	24828-207	24822-097	24827-027
3	133	310	221	14820-375	14825-375	24827-375	24828-305	24822-075	24827-025
3	133	399	221	14820-395	14825-395	24827-395	24828-305	24822-095	24827-025
3	133	399	310	14820-397	14825-397	24827-397	24828-307	24822-097	24827-027

Accessories

Clip for horizontal rail mounting PU 2 pieces	24820-002
Adhesive base Height 5 mm, PU 10 pieces (adhesive base, screw, washer)	24827-005
Adhesive base Height 7 mm, PU 10 pieces (adhesive base, screw, washer)	24827-007
Adhesive base Height 9 mm, PU 10 pieces (adhesive base, screw, washer)	24827-009
Assembly tool plastic, with Torx T10 bit, 1 kit	24820-001
Plastic tip-up foot anthracite, similar to RAL 7016, 4 pieces	20603-002
Stacking aid anthracite, similar to RAL 7016, PA, UL 94 V-0, PU 4 pieces	20603-003
Plastic foot PC, UL 94 V-0, for material thickness 1 ... 3, 1 piece (SPQ 50)	60224-009

Note

- Modified or customized cases on request