

Han E LP-Adapter

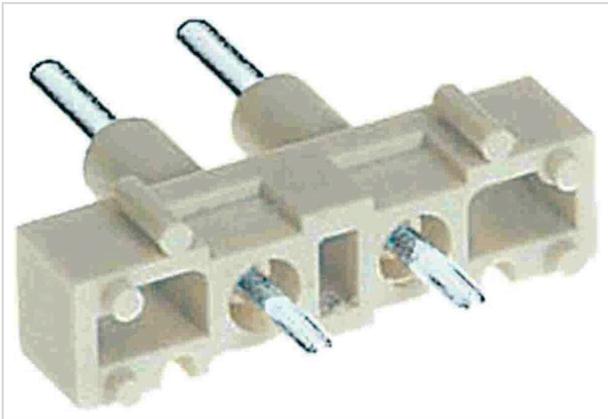


Image is for illustration purposes only. Please refer to product description.

Part number	09 33 000 9996
Specification	Han E LP-Adapter
HARTING eCatalogue	https://harting.com/09330009996

Identification

Category	Accessories
Type of accessory	PCB adapter
Description of the accessory	In the Han E [®] crimp insert

Version

Gender	Male Female
--------	----------------

Technical characteristics

Rated current	16 A
Rated voltage	500 V
Rated impulse voltage	6 kV
Pollution degree	3
Limiting temperature	-40 ... +125 °C

Material properties

Material (insert)	Polycarbonate (PC)
RoHS	compliant with exemption
RoHS exemptions	6(c): Copper alloy containing up to 4 % lead by weight
ELV status	compliant with exemption
China RoHS	50
REACH Annex XVII substances	Not contained
REACH ANNEX XIV substances	Not contained



Pushing Performance
Since 1945

Material properties

REACH SVHC substances	Yes
REACH SVHC substances	Lead
ECHA SCIP number	b51e5b97-eeb5-438b-8538-f1771d43c17d
California Proposition 65 substances	Yes
California Proposition 65 substances	Lead Nickel
Fire protection on railway vehicles	EN 45545-2 (2020-08)
Requirement set with Hazard Levels	R22 (HL 1-3) R23 (HL 1-3)

Commercial data

Packaging size	50
Net weight	3.16 g
Country of origin	Romania
European customs tariff number	85366990
GTIN	5713140050709
eCl@ss	27460201 PCB connector (board connector)
ETIM	EC002637
UNSPSC 24.0	39121415