


HP Jornada
600 Series
Handheld PCs



HP Jornada
820 Handheld PC

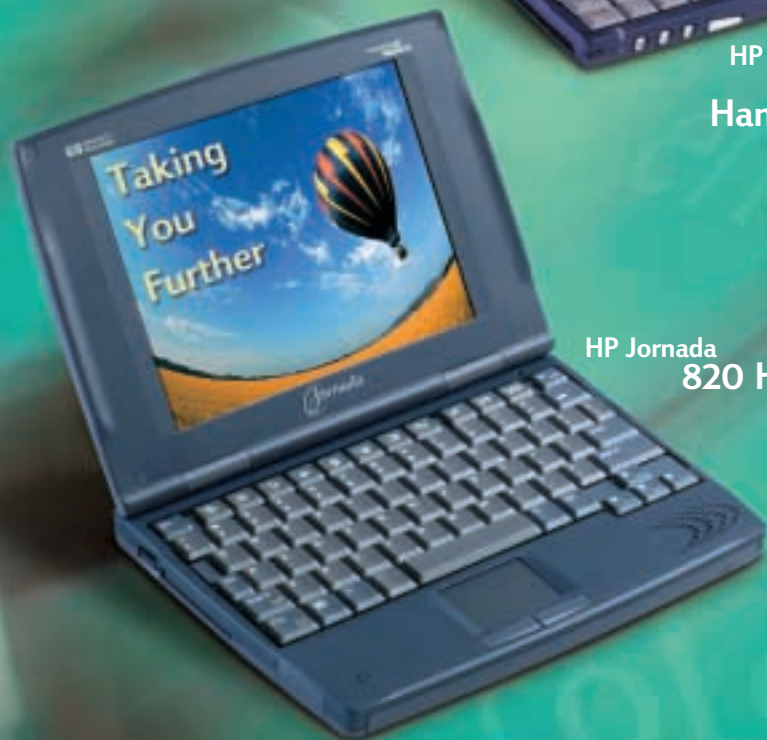

HP Jornada
430 Series
Palm-size PCs

PC Companion Products
Jornada
HP

HP *Jornada*



HP Jornada 430 Series Palm-size PCs

Part Number

- HP F1796A #001—HP Jornada 430
- HP F1796A #ABA—HP Jornada 430se

Processor

- 133MHz 32-bit Hitachi SH7709a processor

Memory

- 16MB RAM
- 8MB ROM

Display

- 240 × 320 pixels LCD
- 16-bit; 65,536 colors (selectable)
- CSTN backlit

Input

- Pen-and-touch interface (stylus included)
- CIC Jot Pro
- On-screen keyboard
- 4 user-configurable quick launch screen icons
- 4 quick keys (Record, Exit, Start, and Scroll/Action)—can be disabled

Power

- One standard Lithium-Ion battery
- 7 hours¹ of battery life
- AC adapter

Dimensions

- 5.1 × 3.2 × 0.9 in (13 × 8.1 × 2.2 cm)

Weight

- 8.8 oz (250 g) with standard battery

Ports/Slots

- One IrDA infrared port
- One RS232 serial port
- One CompactFlash Type I and II card slot

Printer Ready

- N/A

Operating System

- Microsoft[®] Windows[®] CE 2.11

Personal Information Management

- HP easy contacts²
- HP voice contacts^{2,3}
- Microsoft Pocket Outlook (Calendar, Tasks, Contacts, Inbox)
- Microsoft Outlook 2000 (full retail desktop version)⁴

Presentation/Word Processing

- Note Taker
- WhatWare[™] HPC Notes[™] 3.0 Lite, HPC Notes 2.03, and HPC Spell⁵

Financial Management

- LandWare OmniSolve^{™2}

Communications

- Microsoft Channels browser
- AvantGo AvantGo.com^{™2,3}
- Utopiasoft[™] Hum[™] 1.61²
- Audible AudiblePlayer[™] 1.0 for Windows CE and AudibleManager[™] 2.0^{2,3}
- Trio[®] PhoneManager 2.0^{2,3}

Connectivity

- Microsoft ActiveSync[®]

Other Software

- EZOS[®] EzExplorer^{™2}
- Voice Recorder
- BSQUARE bTASK^{™2}
- Sierra Imaging Image Expert[®] CE 2.0^{2,3}
- HP Jornada settings
- HP Jornada backup
- Inso[®] Quick View Plus^{™2,6}
- World Clock
- Solitaire
- Sampler songs from *Chang and Eng—The Musical and Echoboy*
- Sample skins for Hum MP3 player

Warranty

- 1 year std. (optional extended warranty available)

HP Jornada 600 Series Handheld PCs

Part Number

- HP F1262A—HP Jornada 680 (with internal modem)
- HP F1263A—HP Jornada 680e (without internal modem)
- HP F1813A—HP Jornada 690 (with internal modem)
- HP F1814A—HP Jornada 690e (without internal modem)

Processor

- 133MHz 32-bit Hitachi SH3 processor

Memory

- 16MB RAM; upgradable (HP Jornada 680)
- 32MB RAM (HP Jornada 690)
- Burst Mode ROM; upgradable

Display

- 6.5-in (16.7-cm) LCD; 65,536 colors
- 640 × 240 pixels on screen
- 1024 × 768 pixels on external monitor

Input

- Large (76% full-size) keyboard
- Stylus and touchscreen

Power

- Lithium-Ion rechargeable battery
- One 3V CR2032 coin-cell backup battery
- Up to 8 hours¹ of battery life
- AC adapter

Dimensions

- 7.4 × 3.7 × 1.3 in (18.9 × 9.5 × 3.4 cm)

Weight

- 1.1 lbs (510 g) with standard battery

Ports/Slots

- Serial port (RS-232C)
- Fast IrDA-compliant port
- Modem port (RJ11)
- One PC Card Type II card slot
- One CompactFlash Type I card slot
- Audio speaker and microphone

Printer Ready

- Direct printing via IrDA or serial port to PCL printers

Operating System

- Microsoft Windows CE, Handheld PC Professional Edition

Personal Information Management

- Microsoft Pocket Outlook (Calendar, Tasks, Contacts, Inbox)
- Microsoft Outlook 2000 (full retail desktop version)⁴
- HP Jornada viewer
- HP quick pad

Presentation/Word Processing

- Microsoft Pocket Word
- Microsoft Pocket PowerPoint
- HP Jornada show

Financial Management

- Microsoft Pocket Excel
- Microsoft Pocket Access
- LandWare OmniSolve^{™5}
- On The Go Software[™] Pocket Quicken^{™7}

Communications

- Internal 56Kbps fax modem⁸
- Microsoft Pocket Internet Explorer
- HP Jornada dialup
- BSQUARE bFAX[™] Pro⁵

Connectivity

- Microsoft ActiveSync
- Starfish[™] TrueSync[™] CE 2.0²

Other Software

- HP Jornada settings, backup, hot keys, macro, power, country selector
- Microsoft PowerPoint Viewer/Converter
- Inso Outside In^{™5}
- BSQUARE bFIND^{™5}
- Trio PhoneManager 2.0⁵
- Sierra Imaging Image Expert CE 2.0²
- WESTTEK[™] JETCET[™] PRINT HP Lite and JETCET Print 2.0 trial copy²

Warranty

- 1 year std. (optional extended warranty available)

HP Jornada 820 Handheld PC

Part Number

- HP F1260A—HP Jornada 820 (with internal modem)
- HP F1261A—HP Jornada 820e (without internal modem)

Processor

- 190MHz Intel StrongARM[™] RISC processor

Memory

- 16MB RAM
- 16MB Burst Mode ROM; upgradable

Display

- 8.2-in (21.0-cm) VGA CSTN screen
- 640 × 480 pixels on screen
- 1024 × 768 pixels on external monitor

Input

- Touch-typeable (90% full-size) keyboard
- Integrated touch pad

Power

- Lithium-Ion rechargeable battery
- Two 3V CR2032 coin-cell backup batteries
- Up to 10 hours¹ of battery life
- AC adapter

Dimensions

- 9.7 × 7.0 × 1.3 in (24.6 × 17.8 × 3.3 cm)

Weight

- 2.5 lbs (1.1 kg) with standard battery

Ports/Slots

- Serial port (RS-232C)
- Fast IrDA-compliant port
- Monitor (DB15) and modem (RJ11) ports
- Universal Serial Bus (USB) host support
- One PC Card Type II card slot
- One CompactFlash Type II card slot
- Audio speaker and microphone

Printer Ready

- Direct printing via IrDA or serial port to PCL printers

Operating System

- Microsoft Windows CE, Handheld PC Professional Edition

Personal Information Management

- Microsoft Pocket Outlook (Calendar, Tasks, Contacts, Inbox)
- HP Jornada viewer

Presentation/Word Processing

- Microsoft Pocket Word
- Microsoft Pocket PowerPoint
- HP Jornada show

Financial Management

- Microsoft Pocket Excel
- Microsoft Pocket Access
- LandWare OmniSolve^{™5}

Communications

- Internal 56Kbps fax modem⁸
- Microsoft Pocket Internet Explorer
- HP Jornada dialup
- BSQUARE bFAX Pro⁵

Connectivity

- Microsoft ActiveSync
- Starfish TrueSync CE 2.0²

Other Software

- HP Jornada hot keys, settings, backup
- Inso Outside In^{™5}
- BSQUARE bFIND^{™5}
- Trio PhoneManager 2.0⁵
- Sierra Imaging Image Expert CE 2.0²
- WESTTEK[™] JETCET[™] PRINT HP Lite and JETCET Print 2.0 trial copy²

Warranty

- 1 year std. (optional extended warranty available)

¹ Estimated battery life. Actual battery life will vary based on usage.

² Available in English only.

³ Not included with the HP Jornada 430 Palm-size PC.

⁴ Microsoft Outlook 2000 is not available in Portuguese or Chinese.

⁵ Available in English for North America, Europe, Latin America, and Asia Pacific only. Trio PhoneManager is downloadable from the Web for U.S. users.

⁶ Not included with the HP Jornada 430se Palm-size PC.

⁷ Available for U.S. only.

⁸ Model with internal modem may not be available in some countries. Please check with your reseller for details.

Microsoft, Windows, the Windows CE logo, and ActiveSync are either registered trademarks or trademarks of Microsoft Corporation in the United States and/or other countries. OmniSolve is a trademark of LandWare, Inc. bFIND, bTASK, and bFAX are trademarks or registered trademarks of BSQUARE Corporation. Starfish and TrueSync are trademarks of Starfish Software. Trio is a registered trademark of Trio AB. Inso, Outside In, and Quick View Plus are registered trademarks of Inso Corporation. Quicken is a registered trademark of Intuit Inc. in the United States and/or other countries used by On the Go Software under license. On the Go Software is a registered trademark of On the Go Software, Inc. EZOS, EZOS EzExplorer, and EzExplorer are either registered trademarks or trademarks of EZOS s.a. in Belgium and/or other countries. Image Expert is a registered trademark of Sierra Imaging. StrongARM is a trademark of ARM, Ltd. WESTTEK and JETCET are trademarks of WESTTEK, L.L.C. Utopiasoft and Hum are trademarks of Utopiasoft. AudiblePlayer and AudibleManager are trademarks of Audible Inc. HPC Notes and WhatWare are trademarks of WhatWare Corporation. AvantGo.com is a trademark of AvantGo, Inc. All other brands and product names are trademarks or registered trademarks of their respective companies.

In a continuing effort to improve the quality of our products, technical and environmental information in this document is subject to change without notice.

© Copyright Hewlett-Packard Company 1999. All Rights Reserved. Reproduction, adaptation, or translation without prior written permission is prohibited, except as allowed under the copyright laws.

Printed in the U.S.A. 11/99

Powered by



Microsoft[®]
Windows[®]CE
Palm-size PC

Powered by



Microsoft[®]
Windows[®]CE
Handheld PC