

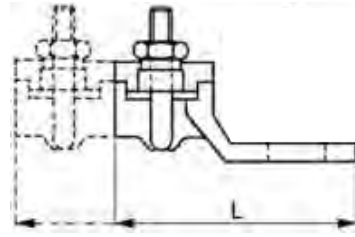


Mechanical Connectors





General features

- ✓ Mechanical brass connectors are normally fitted with 60 Kg zinc-plated U bolts.

For bronze U bolts please suffix the PN with the letter « B ».







Straight mechanical connectors with one tap

 mm²	 Item code	 Part No.		L
6 - 50	7600761	RDB201	25	43
6 - 50	7600762	RDB201B	25	43
6 - 70	7600771	RDB211	10	48
6 - 70	7600772	RDB211B	10	48
25 - 150	7600781	RDB301	5	63
25 - 150	7600782	RDB301B	5	63



RDB Series

Straight mechanical connectors with one or two taps

 mm²	 Item code	 Part No.		L
6 - 50	7600801	R1D201	25	43
6 - 50	7600802	R1D201B	25	43
6 - 50	7600901	R2D201	15	43
6 - 50	7600902	R2D201B	15	43







R1D Series



R2D Series





Mechanical tap connectors

 mm²	 Item code	 Part No.		L
6 - 50	7600831	DB202	25	21
6 - 50	7600832	DB202B	25	21




DB Series

“T” connectors

 mm²	 Item code	 Part No.		L
6 - 50	7600861	BT9	10	47
6 - 50	7600862	BT9B	10	47
6 - 70	7600871	BT11	10	57
6 - 70	7600872	BT11B	10	57
25 - 150	7600881	BT16	10	78
25 - 150	7600882	BT16B	10	78



BT Series

 Nominal size (mm²)

 Packing

Unless stated otherwise, all dimensions are in millimeters.