



### D9 - BSP Male Stud (DIN 3852 Form A)

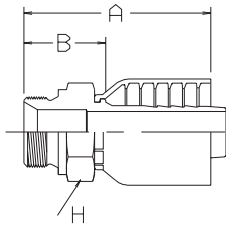


XXXXX-YY-YY Part Number	Hose I.D.				BSP thread	A mm	B mm	H mm
	DN	inch	Size	mm				
1D948-2-4	6	1/4	-4	6,3	1/8-28	46	22	14
1D948-4-4	6	1/4	-4	6,3	1/4-19	51	27	19
1D948-8-4	6	1/4	-4	6,4	1/2-14	56	33	27
1D948-6-5	8	5/16	-5	7,9	3/8-19	55	31	22
1D948-6-6	10	3/8	-6	9,5	3/8-19	54	31	22
1D948-8-6	10	3/8	-6	9,5	3/8-19	56	33	27
1D948-6-8	12	1/2	-8	12,7	3/8-19	54	30	22
1D948-8-8	12	1/2	-8	12,7	1/2-14	57	33	27
1D948-10-10	16	5/8	-10	15,9	5/8-14	61	36	30
1D948-12-10	16	5/8	-10	15,9	3/4-14	62	37	32
1D948-12-12	20	3/4	-12	19,0	3/4-14	62	36	32
1D948-16-12	20	3/4	-12	19,1	1-11	68	42	41
1D948-16-16	25	1	-16	25,4	1-11	72	42	41

### 91 - BSP Taper Male

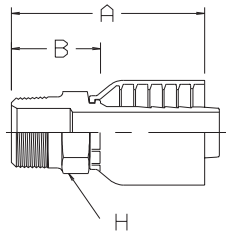

XXXXX-YY-YY Part Number	Hose I.D.				BSP thread	A mm	B mm	H mm
	DN	inch	Size	mm				
19148-4-6	10	3/8	-6	9,5	1/4-19	47	24	14
19148-8-6	10	3/8	-6	9,5	1/2-14	57	34	22
19148-8-8	12	1/2	-8	12,7	1/2-14	57	33	22
19148-16-16	25	1	-16	25,4	1-11	72	42	36

### 01 - NPTF Male Pipe

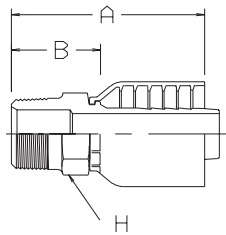

XXXXX-YY-YY Part Number	Hose I.D.				NPTF thread	A mm	B mm	H mm
	DN	inch	Size	mm				
10148-2-4	6	1/4	-4	6,4	1/8-27	47	23	12
10148-4-4	6	1/4	-4	6,4	1/4-18	53	29	14
10148-6-5	8	5/16	-5	7,9	3/8-18	55	31	19
10148-6-6	10	3/8	-6	9,5	3/8-18	54	31	19
10148-8-6	10	3/8	-6	9,5	1/2-14	55	32	22
10148-8-8	12	1/2	-8	12,7	1/2-14	62	38	22
10148-12-12	20	3/4	-12	19,0	3/4-14	60	34	27

Only items priced in current price list are carried in stock.  
Material: zinc plated mild steel.  
Dimensions shown may be changed at any time without prior notice.