

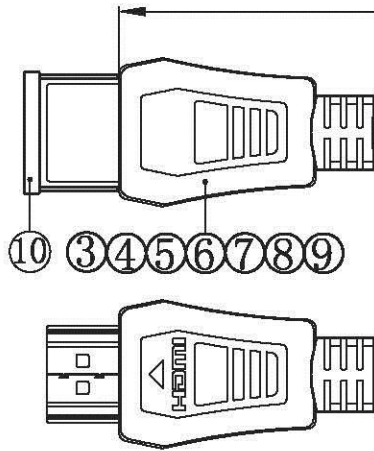
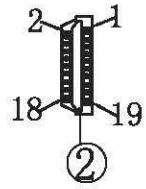


HDMI 19M

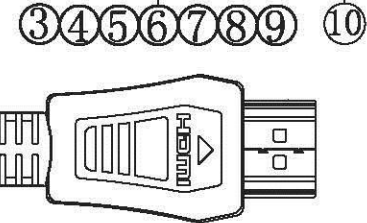


L (mm)

HDMI 19M

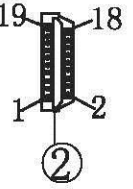

Item no.	Length (L)	Tolerance
11.99.5735	5000 mm	± 50 mm
11.99.5740	10000 mm	± 70 mm

Pin Out

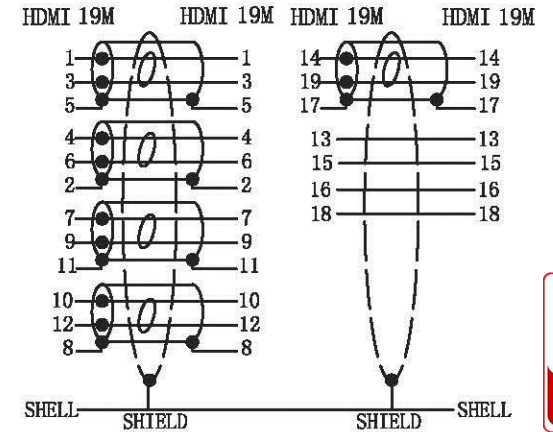

NO	Material	Specification	Unit	QTY	Remarks
①	Cable	UL20276 (1P*28#+AL+D+M)*5C+3C*28#+1C*28#+AL+D+B OD7.3 1.4V 160AL black printing: High Speed HDMI™ Cable With Ethernet E119932-T 兄 AWM STYLE 21104 80°C 30V VW-1 COPARTNER RoHS	M	L	
②	Connector	HDMI 19P M Nickel Plated RoHS	PCS	2	
③	Tin line	Lead-free Green Wire ODO.8 1000g RoHS	G	0.56	20*14g
④	Tube (1)	Black Shrink-Heat Tube OD:1.0MM RoHS	M	0.220	10*22mm
⑤	Tube (2)	Black Shrink-Heat Tube OD:2.5MM RoHS	M	0.110	10*11mm
⑥	Inner mold	LD-PE RoHS	KG	0.004	
⑦	Mask Tape	2.3CM RoHS	M	0.12	2*60mm
⑧	Copper foil	2.9CM Copper Foil RoHS	M	0.12	2*60mm
⑨	Outer mold	Black PVC A813 60P RoHS	KG	0.018	
⑩	Dust cover	Dust cover PE Material RoHS	PCS	2PCS	

Test parameters:insulation resistance:10mΩ conduction impedance:5Ω high-pressure test:300v

11.99.5735 (5.0m); 11.99.5740 (10.0m)		
VALUE HDMI High Speed Cable, w/Ethernet, A-A, M/M, LSOH, black		
	Unit: mm	CHECKED BY ENGINEER
	Version: A/0	APPROVED BY SALES