



MASTERColour CDM-R111

MASTERColour CDM-R111 70W/830 GX8.5 24D 1CT

The MASTER Colour CDM-R111 combines the trendy look of the 111mm aluminium reflector halogen lamps with the long life, high energy efficiency and crisp white light of MASTER Colour CDM

Product data

• General Characteristics

Cap-Base	GX8.5
Bulb	R111 [R 111mm]
Bulb Finish	Reflector
Burning Position	any [Any/Universal]
Life to 5% failures EL	4000 hr
Life to 10% failures EL	5000 hr
Life to 20% failures EL	7500 hr
Life to 50% failures EL	12000 hr

• Light Technical Characteristics

Beam Description	Narrow Flood
Beam Angle	24 D
Technical Beam Angle	18 (min), 23 (nom), 28 (max) D
Luminous Intensity	14500 cd
Colour Code	830 [CCT of 3000K]
Colour Rendering Index	85 Ra8
Colour Designation	Warm white
Colour Temperature	3000 K
Colour Temperature Technical	2800 K
Lamp Luminous Flux EL	2850 Lm
LLMF - end nominal lifetime	50 %
Chromaticity Coordinate X	0.444 -
Chromaticity Coordinate Y	0.394 -
Luminous flux in 90° cone	2800 Lm

• Electrical Characteristics

System Power EL	83 W
Lamp Wattage	70 W
Lamp Wattage EL	70 W
Lamp Wattage EL 25°C, Rated	73.0 W
Lamp Voltage	83 V
Lamp Current EL	0.88 A
Ignition Time	30 (max) s
Run-up time 90%	3 (max) min
Re-ignition Time [min]	15 (max) min
Dimmable	no
Warm-up Time to 60% Light Outp	120 s

• Environmental Characteristics

Energy Efficiency Label (EEL)	B
Mercury (Hg) Content	7.5 mg
Energy consumption kWh/1000h	80 kWh

• UV-related Characteristics

Damage Factor D/fc PET (NIOSH)	0.3 (max) - 8 (min) h500lx
--------------------------------	----------------------------

• Measuring Conditions

Switching cycle	1050X
-----------------	-------



asimpleswitch.com

PHILIPS

MASTERC colour CDM-R111

• Product Dimensions

Overall Length C	95 (max) mm
Diameter D	111 (max) mm
Overall Length C [inch]	3.6 (max) in

• Product Data

Order code	207210 10
Full product code	871150020721010
Full product name	MASTERC colour CDM-R111 70W/830 GX8.5 24D 1CT
Order product name	MASTERC CDM-R111 70W/830 GX8.5 24D 1CT


Pieces per pack	1
Packing configuration	6
Packs per outerbox	6
Bar code on pack - EAN1	8711500207210
Bar code on outerbox - EAN3	8711500207227
Logistic code(s) - 12NC	928091405330
ILCOS code	MRS/UB-70/830-H-GX8.5-111/88/24
Net weight per piece	0.096 kg

Warnings and Safety

- Control gear must include end-of-life protection (IEC61167, IEC 62035)
- Use only with electronic control gear. 35W/830 lamps may also use electromagnetic gear.

- A lamp breaking is extremely unlikely to have any impact on your health. If a lamp breaks, ventilate the room for 30 minutes and remove the parts, preferably with gloves. Put them in a sealed plastic bag and take it to your local waste facilities for recycling. Do not use a vacuum cleaner.

Dimensional drawing

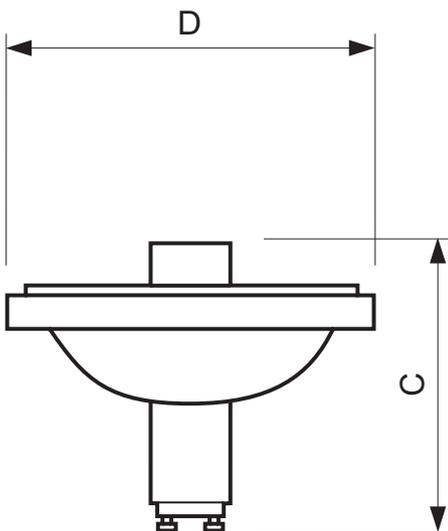


GX8.5

MASTERC colour CDM-R111 70W/830 GX8.5 24D 1CT

Product	C (Max)	D (Max)
CDM-R111 70W/830 24D	95	111

Photometric data

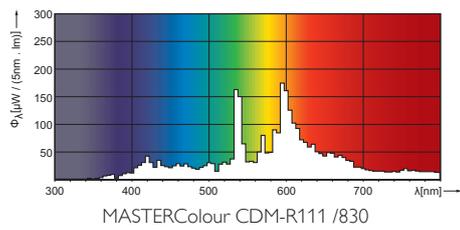

© 2014 Koninklijke Philips N.V. (Royal Philips)
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips N.V. (Royal Philips) or their respective owners.

www.philips.com/lighting

2014, November 30
data subject to change