


## SMALL PIGMY 24V

SLD7102X2DC

1,6 W - 200lm - 2700K



15.000h

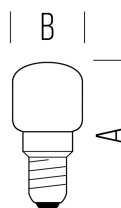

DIMENSIONS	A	B	C
1	56	25	

GENERAL INFORMATIONS	
Code	SLD7102X2DC
Ean	8031453025069
Family	SMALL PIGMY 24V
Product line	PP
Technology	LED
Operating temperature (° C)	-15 - +40
Years warranty	2

LIGHTING DATA	
Light colour	DL
CCT (K)	2700
Luminous flux (lm)	200
Beam (°)	120
Luminous Efficacy (lm/W)	111
Color rendering (CRI)	>80
Standard Deviation Colour Matching - SDCM	6
Chromatic Coordinates y	0,4033
Chromatic Coordinates x	0,4339

TECHNICAL FEATURES	
Base	E14
Power (W)	1,6
Energy Consumption ON mode (kWh/1000h)	2
Supply voltage (V) / Max (V)	24 / 24
Power frequency (Hz)	DC
Current consumption (mA)	78
Power factor	>0,55
Dimmer compatibility	NO
On/off cycles	30000
Nominal life (h)	15000
Directional / Non-directional	NDLS
Mains voltage YES / NO	NMLS
Factor Total Mains - FTM	0,926
Survival factor (2019/2015)	0,9
Lumen Maintenance factor (2019/2015)	0,948

PACKAGING	
Packaging	BOX
Pack	20 / 100
Gross weight (Kg)	2.3
Net weight (Kg)	0.012

**SMALL PIGMY 24V**

SLD7102X2DC

1,6W - 200lm - 2700K



per cancelli / for gates