

## FEATURES

- Self-drilling, self-tapping screw capable of drilling its own hole, and self-tap the hole, saving time and effort not having to pilot drill
- Ideal for a multitude of industries and applications
- C1022 case hardened steel, offering great strength
- Bright zinc plated steel for corrosion protection in indoor applications
- Pan head design helps distribute the load over a large surface area, meaning that they offer a good clamping force
- Pozi drive offers good torque whilst driving
- Conforms to DIN 7504N

## RS PRO Pozi Pan Head Self-drilling Screws BZP

RS Stock No: see below



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

### Product Description

Self-drilling screws offer advantages over conventional self-tapping screws in that they eliminate the need to drill a pilot hole before insertion. This can save both time and effort in many fastening applications, whilst delivering the same security and versatility of a conventional self-tapping screw.

Self-drilling screws should always be installed using a power-driver and are therefore particularly suited to fast production environments.

They can be used in light and heavy gauge sheet metals, soft plastics, etc., and are ideal for applications in heating and air conditioning, metal and fibreglass fabrication industries, as examples. Ideal for a multitude of applications including electrical, plumbing, building, or the DIY enthusiast.


The pan head design offers a good surface area under the head, resulting in a high clamping pressure capability.

These pozi pan head self-drilling screws are made from C1022 case-hardened steel, offering great strength, and conform to DIN 7504N.

### General Specifications

<b>Diameter</b>	M3.5, M4.2, M4.8
<b>Length</b>	9.5 - 25mm
<b>Head Style</b>	Pan Head
<b>Drive Type</b>	Pozi
<b>Pozi Drive No.</b>	2
<b>Material</b>	C1022 Steel Case-hardened
<b>Finish</b>	Bright Zinc Plated (BZP)
<b>DIN</b>	7504N

## Self Drilling Screws

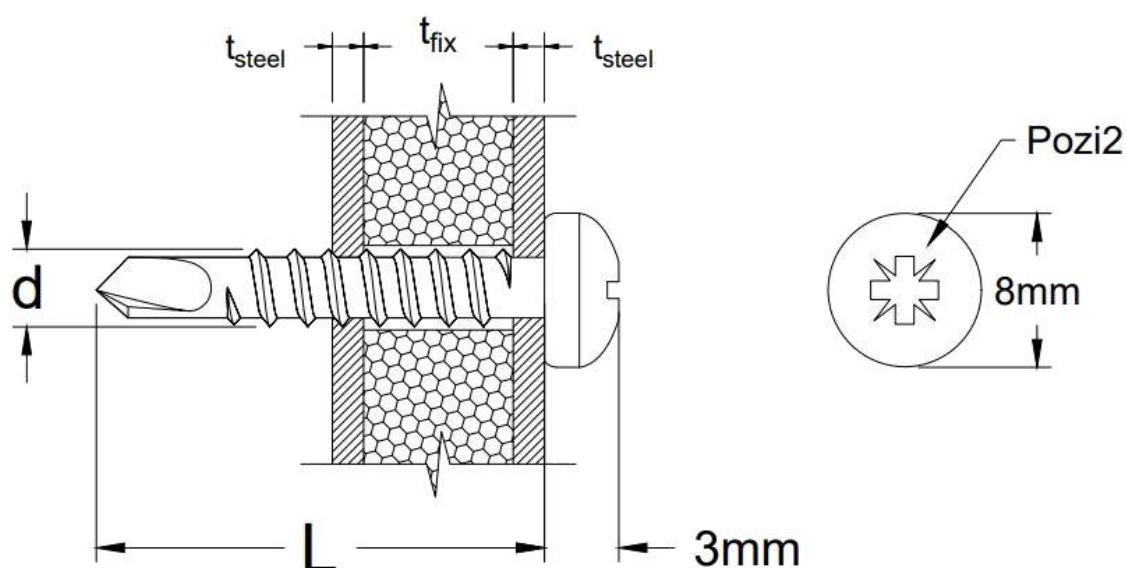

RS Stock Code	Thread Dia (mm) d	Length (mm) L	Steel Thickness t steel	Max Fixture Thickness (mm) t fix	Point Type
5465929	3.5	9.5	1.2-2.5	1	2 Point
5465935	3.5	13	1.2-2.5	5	2 Point
5465941	3.5	19	1.2-2.5	11	2 Point
5465957	4.2	13	1.2-2.5	5	2 Point
5465963	4.2	16	1.2-2.5	8	2 Point
5465979	4.2	19	1.2-2.5	11	2 Point
5465985	4.2	25	1.2-2.5	17	2 Point
5465991	4.8	13	1.2-3.0	2	3 Point
5466001	4.8	19	1.2-3.0	5	3 Point
5466017	4.8	25	1.2-3.0	11	3 Point