

Product datasheet

Specifications



FRONT PLATE TARIF NSX250 W300

LVS03259

EAN Code: 3606481873088

Main

Range	PrismaSeT
Range of product	PrismaSeT G
Product or component type	Front plate
Accessory / separate part category	Installation accessory
Range compatibility	PrismaSeT PrismaSeT G duct
Type of front plate	Cut-out
Installed device	ComPact: fixed INV100 - control: direct front rotary handle - vertical installation ComPact: fixed INV160 - control: direct front rotary handle - vertical installation ComPact: fixed INV200 - control: direct front rotary handle - vertical installation ComPact: fixed INV250 - control: direct front rotary handle - vertical installation ComPact: fixed NSX100...160 without earth leakage protection - control: toggle - vertical installation ComPact: fixed NSX250 without earth leakage protection - control: toggle - vertical installation ComPact: fixed NSX250 with earth leakage protection - control: toggle - vertical installation
Poles description	1 x 4P: mounting plate support: INV100 vertical installation 1 x 4P: mounting plate support: INV160 vertical installation 1 x 4P: mounting plate support: INV200 vertical installation 1 x 4P: mounting plate support: INV250 vertical installation 1 x 4P: mounting plate support: NSX100...160 vertical installation 1 x 4P: mounting plate support: NSX250 vertical installation

Operating position Superposed

Complementary

Enclosure/cubicle description	Floor-standing duct - width 300 mm Wall-mounted duct - width 300 mm
Number of vertical modules [50 mm]	12
Standards	IEC 61439-2 NF C 15-100 IEC 61439-1
Product certifications	ASTA
Surface finish	Textured Matt
Protective treatment	Electrophoresis treatment and hot-polymerised polyester epoxy powder
Colour	White (RAL 9003)
Height	600 mm
Width	300 mm
Net weight	1.2 kg
Quantity per set	Set of 1

functional unit	300 mm PrismaSeT G floor-standing duct ComPact INV100 fixed direct front rotary handle vertical 4P 1 direct 12
	300 mm PrismaSeT G wall-mounted duct ComPact INV100 fixed direct front rotary handle vertical 4P 1 direct 12
	300 mm PrismaSeT G floor-standing duct ComPact INV100 fixed direct front rotary handle vertical 4P 1 direct
	300 mm PrismaSeT G wall-mounted duct ComPact INV100 fixed direct front rotary handle vertical 4P 1 direct
	300 mm PrismaSeT G floor-standing duct ComPact INV160 fixed direct front rotary handle vertical 4P 1 direct 12
	300 mm PrismaSeT G wall-mounted duct ComPact INV160 fixed direct front rotary handle vertical 4P 1 direct 12
	300 mm PrismaSeT G floor-standing duct ComPact INV160 fixed direct front rotary handle vertical 4P 1 direct
	300 mm PrismaSeT G wall-mounted duct ComPact INV160 fixed direct front rotary handle vertical 4P 1 direct
	300 mm PrismaSeT G floor-standing duct ComPact INV200 fixed direct front rotary handle vertical 4P 1 direct 12
	300 mm PrismaSeT G wall-mounted duct ComPact INV200 fixed direct front rotary handle vertical 4P 1 direct 12
	300 mm PrismaSeT G floor-standing duct ComPact INV200 fixed direct front rotary handle vertical 4P 1 direct
	300 mm PrismaSeT G wall-mounted duct ComPact INV200 fixed direct front rotary handle vertical 4P 1 direct
	300 mm PrismaSeT G floor-standing duct ComPact INV250 fixed direct front rotary handle vertical 4P 1 direct 12
	300 mm PrismaSeT G wall-mounted duct ComPact INV250 fixed direct front rotary handle vertical 4P 1 direct 12
	300 mm PrismaSeT G floor-standing duct ComPact INV250 fixed direct front rotary handle vertical 4P 1 direct
	300 mm PrismaSeT G wall-mounted duct ComPact INV250 fixed direct front rotary handle vertical 4P 1 direct
	300 mm PrismaSeT G floor-standing duct ComPact NSX100...160 without fixed toggle vertical 4P 1 direct
	300 mm PrismaSeT G wall-mounted duct ComPact NSX100...160 without fixed toggle vertical 4P 1 direct
	300 mm PrismaSeT G floor-standing duct ComPact NSX250 without fixed toggle vertical 4P 1 direct
	300 mm PrismaSeT G wall-mounted duct ComPact NSX250 without fixed toggle vertical 4P 1 direct
	300 mm PrismaSeT G floor-standing duct ComPact NSX250 with fixed toggle vertical 4P 1 direct 16
	300 mm PrismaSeT G wall-mounted duct ComPact NSX250 with fixed toggle vertical 4P 1 direct 16

Environment

IP degree of protection	IP30
--------------------------------	------

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	3 cm
Package 1 Width	25 cm
Package 1 Length	60 cm
Package 1 Weight	1.1 kg
Unit Type of Package 2	BB1
Number of Units in Package 2	6
Package 2 Height	16.5 cm
Package 2 Width	53.5 cm
Package 2 Length	82 cm
Package 2 Weight	7.571 kg
Unit Type of Package 3	P12

Number of Units in Package 3	48
Package 3 Height	80 cm
Package 3 Width	80 cm
Package 3 Length	120 cm
Package 3 Weight	72.5 kg

Contractual warranty

Warranty (in months)	18
-----------------------------	----



Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

Environmental footprint

[Environmental Disclosure](#)

[Product Environmental Profile](#)

Use Better

Materials and Substances

Packaging made with recycled cardboard

Yes

Packaging without single use plastic

No

[EU RoHS Directive](#)

Compliant

REACH Regulation

[REACH Declaration](#)

Halogen-free status

Halogen free plastic parts product

PVC free

Yes

Silicone-free

Yes

Use Longer

Lifetime extension

Repair

No

Use Again

Repack and remanufacture

End of life manual availability


No need of specific recycling operations

Take-back

No

Technical Illustration

Dimensions

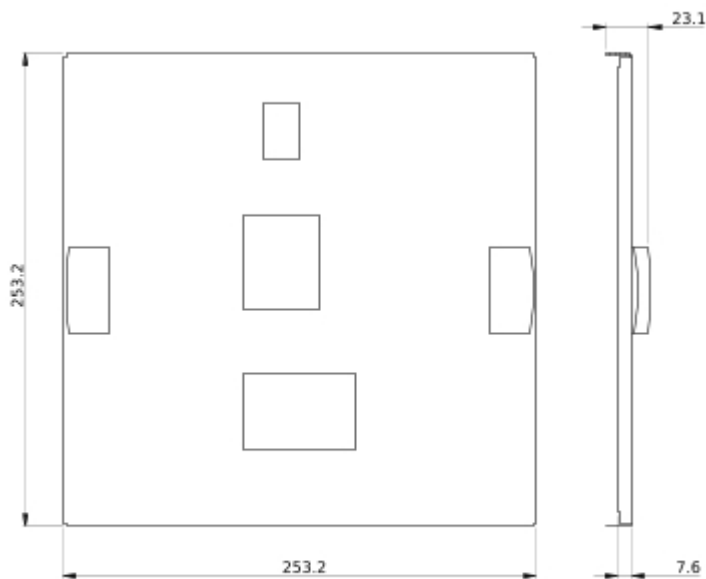

- All dimensions are approximate and are in
- Also see technical documentation.