

SAC-3P-MR/BI SCO - Valve connectors



1409337

<https://www.phoenixcontact.com/in/products/1409337>

Please be informed that the data shown in this PDF document is generated from our online catalog. Please find the complete data in the user documentation. Our general terms of use for downloads are valid.



Valve connectors, 3-position, Plug angled M12, coding: A, on Valve connector BI (11 mm)

Commercial data

Item number	1409337
Packing unit	1 pc
Minimum order quantity	25 pc
Note	Made to order (non-returnable)
Sales key	BF1
Product key	AF1GDA
GTIN	4055626070193
Weight per piece (including packing)	25.6 g
Weight per piece (excluding packing)	25.6 g
Customs tariff number	85366990
Country of origin	PL

SAC-3P-MR/BI SCO - Valve connectors



1409337

<https://www.phoenixcontact.com/in/products/1409337>

Technical data

Product properties

Product type	Valve connector adapter
Number of positions	3
No. of cable outlets	1
Coding	A

Insulation characteristics

Overvoltage category	II
Degree of pollution	3

Connection data

Connection method	M12 connector
Tightening torque	0.6 Nm (Valve connector)

Electrical properties

Insulation resistance	$\geq 100 \text{ M}\Omega$
Nominal voltage U_N	24 V AC
	24 V DC
Nominal current I_N	4 A
Protective circuit	unwired

Mechanical properties

Mechanical data

Insertion/withdrawal cycles	≥ 100
-----------------------------	------------

Material specifications

Flammability rating according to UL 94	HB
Seal material	TPU
Material housing valve plug	TPU
Contact material	CuSn
Contact surface material	Ni/Au
Contact carrier material	PA 66
Contact material	CuSn
Valve plug contact insert material	PA 6.6
Contact surface material	Sn
Material for screw connection	Zinc die-cast, nickel-plated

Signaling

Status display present	No
------------------------	----

Connector

SAC-3P-MR/BI SCO - Valve connectors



1409337

<https://www.phoenixcontact.com/in/products/1409337>

Connection 1

Type	Plug angled M12
Number of positions	3
Coding type	A

Connection 2

Type	Valve connector BI (11 mm)
Number of positions	3
Material	CuSn (Contact)
	Sn (Contact surface)
	PA 6.6 (Contact carriers)
	TPU (Housing)

Environmental and real-life conditions

Ambient conditions

Degree of protection	IP65
	IP67
Ambient temperature (operation)	-25 °C ... 85 °C (valve plug)


Standards and regulations

M12

Standard designation	M12 connector
Standards/specifications	IEC 61076-2-101


Drawings

Schematic diagram

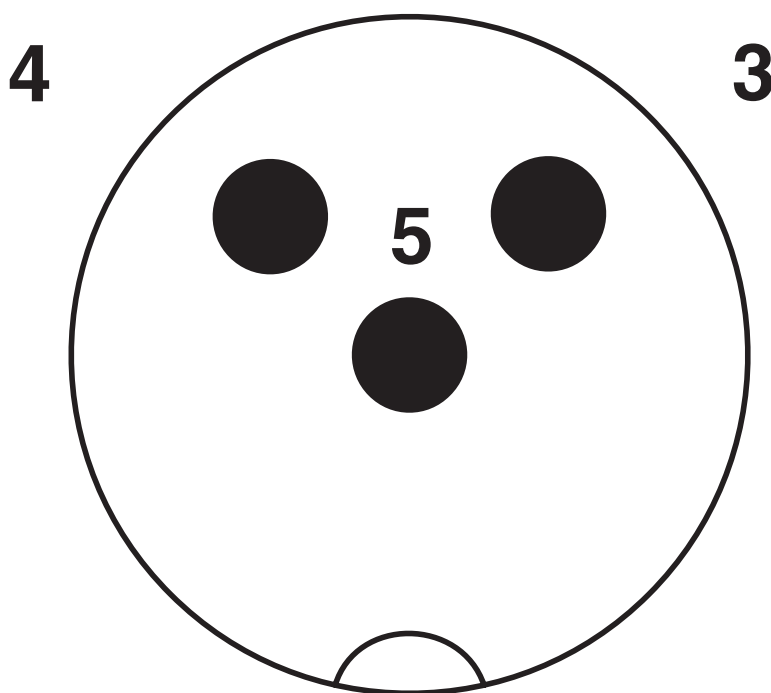

Pin assignment M12 plug, 3-pos., A-coded, view male side

Schematic diagram

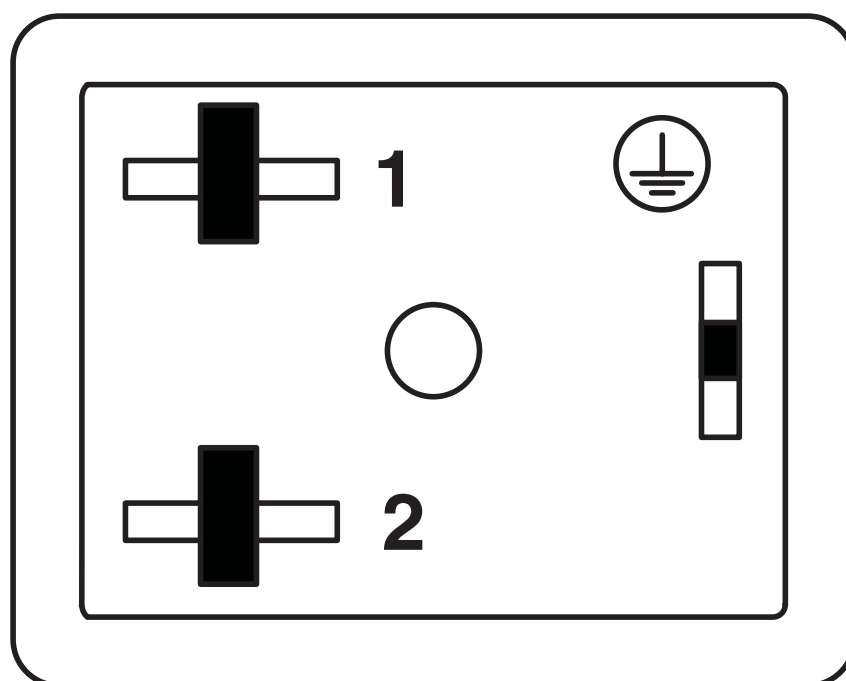


Valve connector pin assignment, type BI

SAC-3P-MR/BI SCO - Valve connectors

1409337

<https://www.phoenixcontact.com/in/products/1409337>

Dimensional drawing

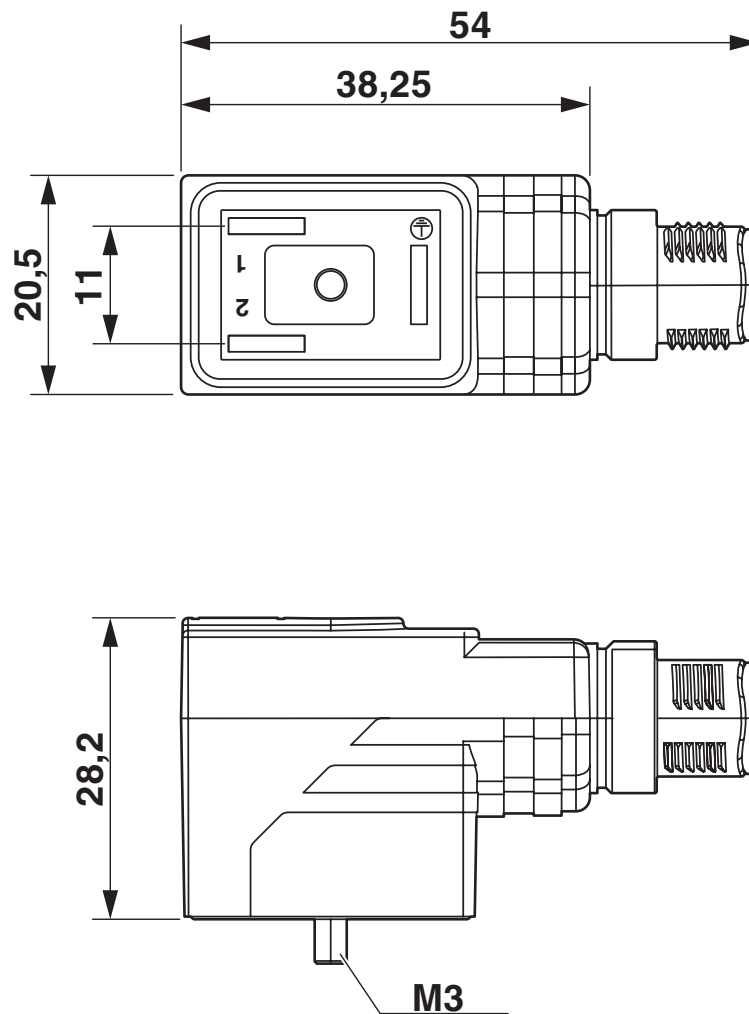

SAC-3P-MR/BI SCO - Valve connectors



1409337

<https://www.phoenixcontact.com/in/products/1409337>

Classifications

ECLASS

ECLASS-11.0	27440105
ECLASS-12.0	27440105
ECLASS-13.0	27440105

ETIM

ETIM 9.0	EC003623
----------	----------

UNSPSC

UNSPSC 21.0	31251500
-------------	----------

SAC-3P-MR/BI SCO - Valve connectors



1409337

<https://www.phoenixcontact.com/in/products/1409337>

Environmental product compliance

EU RoHS	
Fulfills EU RoHS substance requirements	Yes, No exemptions
China RoHS	
Environment friendly use period (EFUP)	EFUP-E
	No hazardous substances above the limits
EU REACH SVHC	
REACH candidate substance (CAS No.)	No substance above 0.1 wt%

SAC-3P-MR/BI SCO - Valve connectors



1409337

<https://www.phoenixcontact.com/in/products/1409337>

Accessories

SAC-3P-FS SCO V/.../... - Connecting cable

1406702

<https://www.phoenixcontact.com/in/products/1406702>



Connecting cable, 3-position, free cable end, on Socket straight M12 SPEEDCON, coding: A, cable length: Free input (0.2 ... 40.0 m), for valve plug adapters

SAC-3P-M12MS/3,0-PUR/M12FS 345 - Sensor/actuator cable

1402560

<https://www.phoenixcontact.com/in/products/1402560>



Sensor/actuator cable, 3-position, PUR halogen-free, black-gray RAL 7021, Plug straight M12, coding: A, on Socket straight M12, coding: A, cable length: 3 m, For valve connector

SAC-3P-MR/BI SCO - Valve connectors



1409337

<https://www.phoenixcontact.com/in/products/1409337>

SAC-3P-M12MS/5,0-PUR/M12FS 345 - Sensor/actuator cable

1402561

<https://www.phoenixcontact.com/in/products/1402561>



Sensor/actuator cable, 3-position, PUR halogen-free, black-gray RAL 7021, Plug straight M12, coding: A, on Socket straight M12, coding: A, cable length: 5 m, For valve connector

SAC-3P-M12MS/10,0-PUR/M12FS 345 - Sensor/actuator cable

1402562

<https://www.phoenixcontact.com/in/products/1402562>



Sensor/actuator cable, 3-position, PUR halogen-free, black-gray RAL 7021, Plug straight M12, coding: A, on Socket straight M12, coding: A, cable length: 10 m, For valve connector

SAC-3P-MR/BI SCO - Valve connectors



1409337

<https://www.phoenixcontact.com/in/products/1409337>

TSD-M 1,2NM - Torque screwdriver

1212224

<https://www.phoenixcontact.com/in/products/1212224>



Torque screw driver, accuracy as per EN ISO 6789 standard, adjustable from 0.3 - 1.2 Nm

SF-BIT-PH 1-70 - Screw insert

1212582

<https://www.phoenixcontact.com/in/products/1212582>



Screw bit, PH crosshead, E6.3-1/4" drive, size: PH 1 x 70 mm, hardened, suitable for holder according to DIN 3126-F6.3/ISO 1173

Phoenix Contact 2025 © - all rights reserved
<https://www.phoenixcontact.com>

PHOENIX CONTACT (I) Pvt. Ltd.
A-58/2, Okhla Industrial Area, Phase - II, New Delhi-110 020

+91.1275.71420
info@phoenixcontact.co.in