

GUILLEMIN SYMETRICAL COUPLINGS POLYPROPYLENE (2430-2437)

Polypropylene Guillemin symetrical couplings for all common fluids of 2nd group.

According to NF-E 29572 standards.

White NBR gasket.



Size : DN40 to DN100

Connection : Female, Male BSP and hose coupling

Min Temperature : +0°C

Max Temperature : +70°C

Max Pressure : 6 Bars

Specifications : Polypropylene fittings

White NBR gasket

According to NF-E 29572

Materials : Polypropylene

GUILLEMIN SYMETRICAL COUPLINGS POLYPROPYLENE (2430-2437)

SPECIFICATIONS :

- Polypropylene couplings
- White NBR gasket (only for coupling with lock ring)
- According to NF-E 29572

USE :

- Irrigation, common fluids of 2nd group
- Min and max Temperature Ts : + 0°C to + 70°C
- Max Pressure Ps : 6 bars

RANGE :

- Hose coupling with lock **Ref.2430** from DN 40-40 to DN 80-76 (with collar for DN50 and 80)
- Reduced coupling with lock **Ref.2432** DN 80-50
- Male coupling with lock **Ref.2433** from DN 40 to DN 80
- Female coupling with lock **Ref.2434** from DN 40 to DN 80
- Cap with lock and chain **Ref.2437** from DN 40 to DN 100

MATERIALS :




Item	Designation	Materials
1	Body	Polypropylene
2	Gasket	White NBR
3	Lock ring	Polypropylene

GUILLEMIN SYMETRICAL COUPLINGS POLYPROPYLENE (2430-2437)


SIZE (in mm) :

- Hose coupling with lock Ref.2430 (with collar for DN50 and 80)

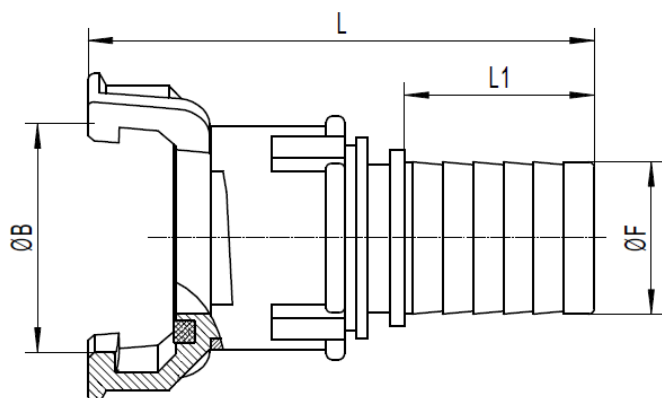


DN	40	50	80
Ø F	40	52	76
Ø B	55	69	103
L	117	125	162
L1	60	49	68
Weig. (Kg)	0.12	0.19	0.41
Ref.	2430040	2430050	2430080

- Reduced coupling with lock Ref.2432

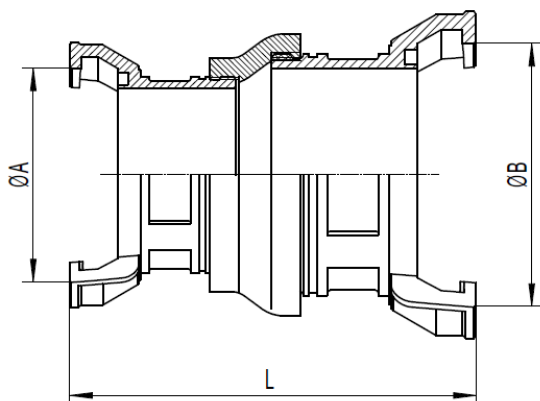

DN	80
DN1	50
Ø A	69
Ø B	103
L	224
Weig. (Kg)	0.68
Ref.	2432081

- Male BSP coupling with lock Ref.2433

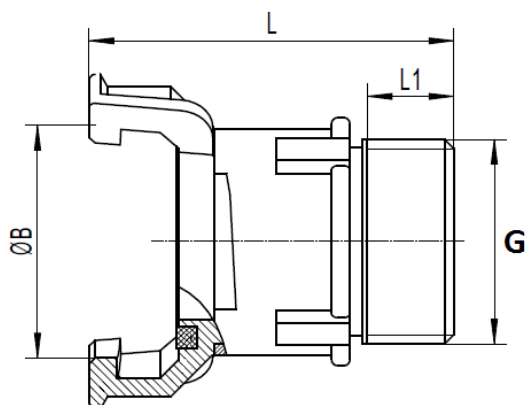


DN	40	50	80
G	1"1/2	2"	3"
Ø B	55	69	103
L	81	92	117
L1	25	30	43
Weig. (Kg)	0.1	0.16	0.34
Ref.	2433040	2433050	2433080

GUILLEMIN SYMETRICAL COUPLINGS POLYPROPYLENE (2430-2437)


SIZE (in mm) :

- Female BSP coupling with lock Ref.2434

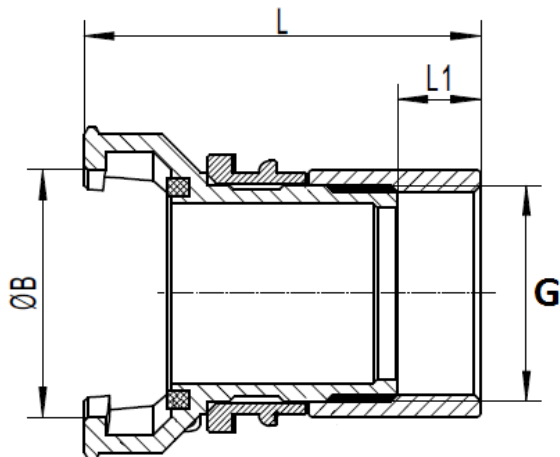

DN	40	50	80
G	1"1/2	2"	3"
Ø B	55	69	103
L	110	131	102
L1	20	25	25
Weig. (Kg)	0.14	0.26	0.53
Ref.	2434040	2434050	2434080

- Cap with lock and chain Ref.2437

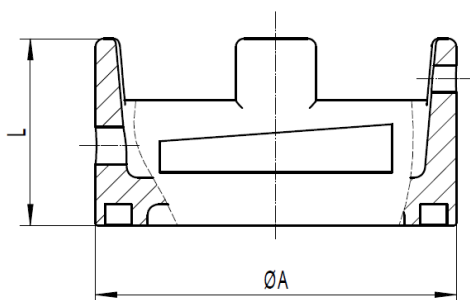

DN	40	50	80
Ø A	54	68	101
L	30	36	44
Weig. (Kg)	0.04	0.06	0.13
Ref.	2437040	2437050	2437080

STANDARDS :

- Manufacturer certified ISO 9001 : 2015
- DIRECTIVE 2014/68/EU : Products excluded from directive (Article 4. § 3)
- Designing according to NF-E 29572
- Threaded female BSP cylindrical according to ISO 7-1 Rp and male BSP conical according to ISO 7-1 R

ADVICE : Our opinion and our advice are not guaranteed and SFERACO shall not be liable for the consequences of damages.
The customer must check the right choice of the products with the real service conditions.