




# Supports et porte-fusibles

Fusibles à capsules français

## Porte-fusibles domestiques

## MSD-MSM

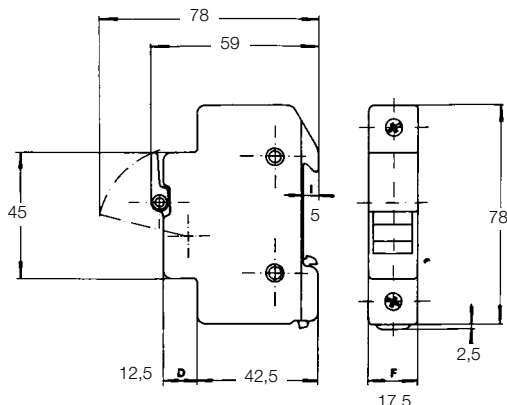

- Indicateur de fusion (120/690V)
- Taille câble :
  - Unipolaire: 1 x 16 mm<sup>2</sup>
  - Unipolaire + neutre: 1 x 10 mm<sup>2</sup>
- IP20



Pôles	Taille	Désignation		N° de réf.		In-Vn	Condit.
		Standard	+ Indicateur	Standard	+ Indicateur		



P219226



N219225

**MSD:** In maxi: 32A ; Vn maxi: 400V

1	8 x 23	13502	13504	C217674	A218707	10A-250V	12
	10 x 25	13602	13604	R201288	Y211023	16A-250V	12
	8 x 31	13702	13704	V214102	F215124	20A-400V	12
	10 x 31	13802	13804	N218190	P219226	25A-400V	12
	10 x 38	13902	13904	S201289	Z211024	32A-400V	12
1+N (1 mod.)	N	14000		W214103			12
	8 x 23	13506	13508	N219225	T222956	10A-250V	12
	10 x 25	13606	13608	Q211545	Z213094	16A-250V	12
	8 x 31	13706	13708	H215632	Z217165	20A-400V	12
	10 x 31	13806	13808	R219757	V222957	25A-400V	12
10 x 38	13906	13908	R211546	A213095	32A-400V	12	

**MSM:** In maxi 16A ; Vn maxi 250V


1 1+N (1 mod.)	5 x 20	05952 05956		J225707 K225708		16A-250V	12 12
-------------------	--------	----------------	--	--------------------	--	----------	----------



J225707

### Picots d'assemblage

N. Mod.	Désignation	N° de réf.	Condit.
2	14030	G215125	10
3	14031	Q216145	10
4	14032	A217166	10

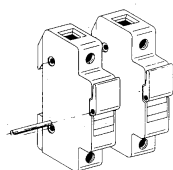

Homologations : IEC 269-3-1, NFC 61.201  
Homolotations : NF/USE (MSD)