

Datasheet

High Barrier Terminal Strips

Technical Data


Number Of Ways	2 to 12
Current Rating	15 amps
Working Voltage	750 V d.c or a.c. peak
Insulation resistance	Greater than 10,000 megaohms
Temperature Range	-55°C to + 100°C



Materials and finishes

Moulding	High impact thermoplastic UL 94V-0 rated
Terminal Plates	Brass, nickel plated
Terminal Tags	Brass, tin plated
Screws	6/32 UNC Binder head, nickel plated

RoHS Compliant

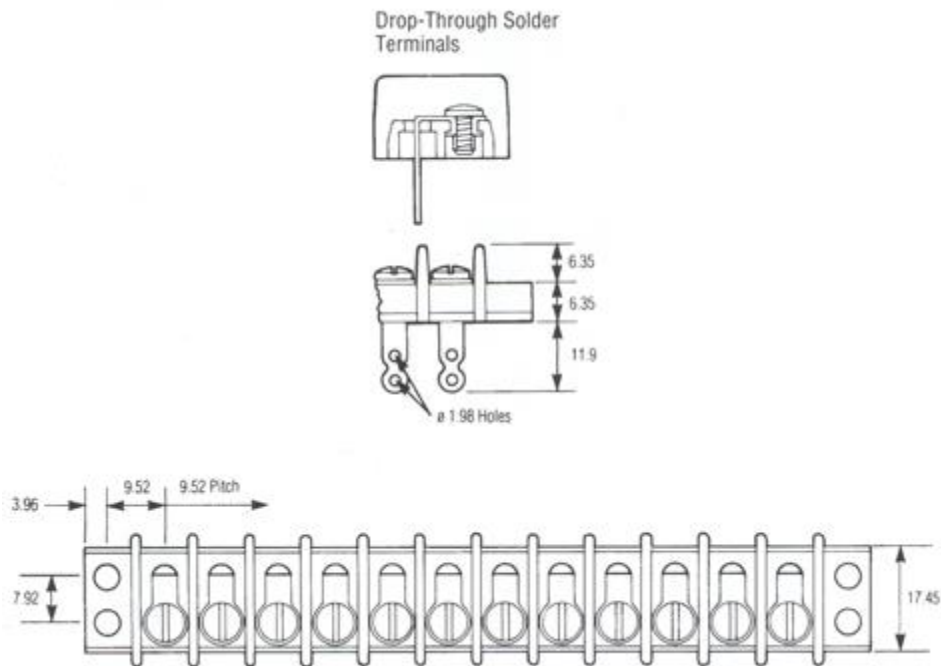

Dimensions

Number Of Terminals	Mounting Hole Centers
2	28.6
3	38.1
4	47.6
5	57.2
6	66.7
7	76.2
8	85.7
9	95.2
10	104.8
11	114.3
12	123.8

Ordering Information

Drop Through Solder Terminals

- 8056064 – 3 Ways
- 8056073 – 6 Ways
- 8056076 – 12 Ways