


LED Micro GX53 6W 450lm (11W) 827 FR

Article number 141878

BAI Ecobasic LED Micro GX53 6W 2700K 120° 450lm (11W) Frosted 230V-240V
74x28mm LED-lamp

Due to its compact dimensions, this lamp is suitable for many indoor applications such as kitchen and cabinet lighting and as a downlight for marking walkways, doors, stairs, etc.

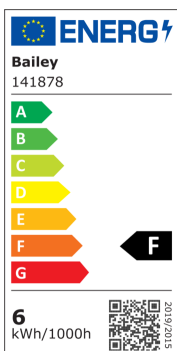

General ETIM properties

ETIM group	Lamps
ETIM class	LED-lamp/Multi-LED
Name	141878
Brand	Bailey
Productseries	Ecobasic LED bulb
Product type	Micro

ETIM specifications

Nominal voltage [V]	220 - 240
Nominal current [mA]	45 - 45
Power factor	0.5
Lamp power [W]	6 - 6
Voltage type	AC
Luminous flux [lm]	450 - 450
Rated luminous flux according to IEC 62612 [lm]	450
Lamp efficacy [lm/W]	75
Colour rendering index CRI	80-89
Lamp shape	Flat round
Filament lamp	No
Type of glass/cover	Frosted
Colour of light according to EN 12464-1	Warm white <3300 K
Socket	GX53
Colour	White
Colour temperature [K]	2700 - 2700
Colour housing	White
Beam angle [°]	120 - 120
Colour consistency (McAdam ellipse)	SDCM6
Dimmable	No
Diameter [mm]	74
Length [mm]	28
Degree of protection (IP)	IP20
Energy Efficiency Index (EEI)	0.15
Lamp designation	Other
Energy efficiency class	F
Min. number of switching cycles	7500
Weighted energy consumption in 1000 hours [kWh]	6
Average nominal lifespan [h]	15000
Remote operation possible	No
With remote control	No
Photobiological safety according to EN 62471	Other
Compatible with Apple HomeKit	No
Compatible with Google Assistant	No
Compatible with Amazon Alexa	No
IFTTT support available	No

Alternative articles



143808



145150

LED Micro GX53 6W
480lm (11W) 840 FR