

Product Compliance

For compliance documentation, visit the product page on TE.com>

EU RoHS Directive 2011/65/EU	Compliant
EU ELV Directive 2000/53/EC	Compliant
China RoHS 2 Directive MIIT Order No 32, 2016	No Restricted Materials Above Threshold
EU REACH Regulation (EC) No. 1907/2006	Current ECHA Candidate List: JAN 2022 (223) Candidate List Declared Against: JAN 2022 (223) Does not contain REACH SVHC
Halogen Content	Low Halogen - Br, Cl, F, I < 900 ppm per homogenous material. Also BFR/CFR/PVC Free
Solder Process Capability	Not applicable for solder process capability

Product Compliance Disclaimer

This information is provided based on reasonable inquiry of our suppliers and represents our current actual knowledge based on the information they provided. This information is subject to change. The part numbers that TE has identified as EU RoHS compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, mercury, PBB, PBDE, DBP, BBP, DEHP, DIBP, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2011/65/EU (RoHS2). Finished electrical and electronic equipment products will be CE marked as required by Directive 2011/65/EU. Components may not be CE marked. Additionally, the part numbers that TE has identified as EU ELV compliant have a maximum concentration of 0.1% by weight in homogenous materials for lead, hexavalent chromium, and mercury, and 0.01% for cadmium, or qualify for an exemption to these limits as defined in the Annexes of Directive 2000/53/EC (ELV). Regarding the REACH Regulation, the information TE provides on SVHC in articles for this part number is based on the latest European Chemicals Agency (ECHA) 'Guidance on requirements for substances in articles' posted at this URL: <https://echa.europa.eu/guidance-documents/guidance-on-reach>


Customers Also Bought

TE Part #926308-1
8P UNIV.M-N-L-CAP

TE Part #3-2176372-8
RQ 0603 121K 0.1% 10PPM 5K RL

TE Part #141456-1
SKT ASSY, SHUR,INS, 4 MM DIA, 22-16 AWG

TE Part #929505-1
FF FLSTE-GEH2X2P

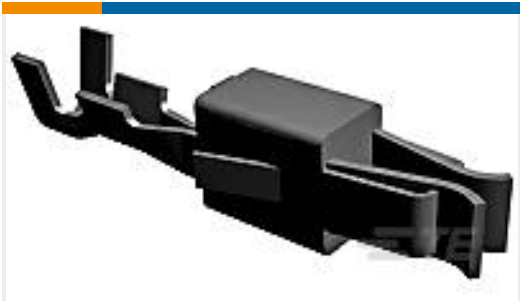

TE Part #1-927770-1
JPT REC 2.8 Contact SWS Au



TE Part #K1002974
Toggle Switch 07-1-2-12



TE Part #166642-000
D-SCE-1K-6.4-50-6



TE Part #928931-2
FF 110 (2.8 X 0.8 MM) TAB PTP
CUZN30



TE Part #CQ50513001
RAY-103-10.0(10)



TE Part #K1144296
Relay-Set 29-311-12-954

Documents

CAD Files

Customer View Model

ENG_CVM_927779-1_A9.3d_igs.zip

English

Customer View Model

ENG_CVM_927779-1_A9.3d_stp.zip

English

Customer View Model

ENG_CVM_927779-1_A9.2d_dxf.zip

English

3D PDF

English

By downloading the CAD file I accept and agree to the [Terms and Conditions](#) of use.

Product Specifications

Application Specification

English

Product Environmental Compliance

TE Material Declaration

English