


Product datasheet

Specifications

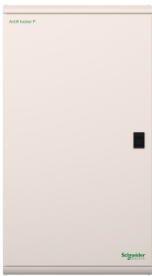

Isobar P B Hybrid Active distribution board, Acti9, 14 ways TP with 6 AFDD ways

SEA9BPN14AFD6

EAN Code: 3606482207783

Main

Range	Acti9
product name	Acti9 Isobar P B
Product or component type	Distribution board
Device application	Distribution
Enclosure type	Standard
Provided equipment	Earth stud Enclosure Door Front cover Pan assembly Neutral terminal block Earth terminal block Blanking plate Removable gland plates
Colour	Cream (RAL 9001)

Complementary

Enclosure mounting	Surface
Poles description	3P + N
[Ie] rated operational current	250 A at 400/415 V AC 250 A at 230/240 V AC
Breaking capacity	25 kA
Overvoltage category	IV
[Ui] rated insulation voltage	500 V
[Uimp] rated impulse withstand voltage	6 kV
Incomer device options	Switch disconnector - 3P + N Switch disconnector - 4P MCCB - 4P Terminal block - 4P Contactor - 4P RCCB - 4P
Protection device options at outgoer	Miniature circuit breaker (MCB) 63 A Residual current circuit breaker with overcurrent protection (RCBO) 45 A 100 mA Residual current circuit breaker with overcurrent protection (RCBO PoN) 45 A 100 mA Arc fault detection device(AFDD) 32 A
Number of ways	14 ways (3P) outgoer 6 ways outgoer AFDD
Enclosure material	Steel
surface treatment	Epoxy

Disclaimer: This documentation is not intended as a substitute for and is not to be used for determining suitability or reliability of these products for specific user applications

Surface finish	Powder paint
Height	862 mm
Width	470 mm
Depth	140 mm
Product weight	18.2 kg

Environment

Standards	BS EN 61439-3
IP degree of protection	IP2X without cover internal conforming to BS EN 60529 IP3x with cover external conforming to BS EN 60529
IK degree of protection	IK05
Ambient air temperature for operation	-35...70 °C
Ambient air temperature for storage	-40...80 °C

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	15.000 cm
Package 1 Width	49.000 cm
Package 1 Length	86.000 cm
Package 1 Weight	18.778 kg
Unit Type of Package 2	PAM
Number of Units in Package 2	12
Package 2 Height	105.000 cm
Package 2 Width	100.000 cm
Package 2 Length	120.000 cm
Package 2 Weight	245.336 kg

Logistical informations

Country of origin	GB
-------------------	----

Contractual warranty

Warranty	18 months
----------	-----------

Environmental Data

Schneider Electric aims to achieve Net Zero status by 2050 through supply chain partnerships, lower impact materials, and circularity via our ongoing “Use Better, Use Longer, Use Again” campaign to extend product lifetimes and recyclability.

[Environmental Data explained >](#)

[How we assess product sustainability >](#)

 Environmental footprint	
Carbon footprint (kg.eq.CO2 per CR, Total Life cycle)	442417
Environmental Disclosure	Product Environmental Profile

Use Better

 Materials and Substances	
Packaging made with recycled cardboard	No
Packaging without single use plastic	No
EU RoHS Directive	Compliant with Exemptions
REACH Regulation	REACH Declaration

Use Again

 Repack and remanufacture	
Circularity Profile	No need of specific recycling operations
Take-back	No

Image of product / Alternate images

Alternative

