


# DX2023



## Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/PNP OUT/AC/DC

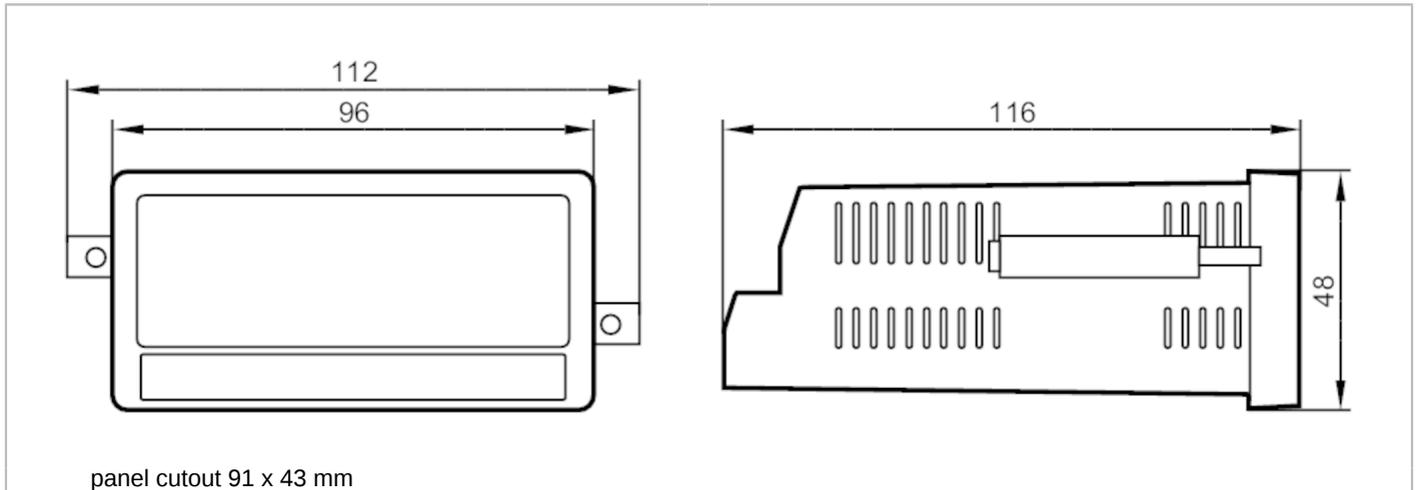

Product characteristics	
Housing	housing for panel mounting
Dimensions [mm]	48 x 112 x 116
Application	
Application	universal evaluation and display for all physical units which can be derived from pulse sequences
Electrical data	
Frequency AC [Hz]	50...60
Operating voltage [V]	115...230 AC / 18...30 DC
Current consumption [mA]	100
Inputs / outputs	
Number of inputs and outputs	Number of digital inputs: 2; Number of digital outputs: 4
Inputs	
Number of digital inputs	2
Outputs	
Number of digital outputs	4
Overload protection	yes
Operating conditions	
Ambient temperature [°C]	-20...60
Storage temperature [°C]	-25...70
Protection	IP 65
Protection rating terminals	IP 20
Tests / approvals	
EMC	EN 61000-6-2 EN 61000-6-3 EN 61000-6-4
Mechanical data	
Weight [g]	352
Housing	housing for panel mounting

# DX2023



## Multifunction display for monitoring revolution, speed and time

DISPLAY/FX460/PNP OUT/AC/DC

Type of mounting	installation in panels or panel cutouts; (panel cutout: 91 x 43 mm)	
Dimensions [mm]	48 x 112 x 116	
Materials	Noryl UL94-V-0	


### Displays / operating elements

Display	colour display	full graphic LCD display, touch screen
---------	----------------	--

### Electrical connection

screw terminals:

#### Connection

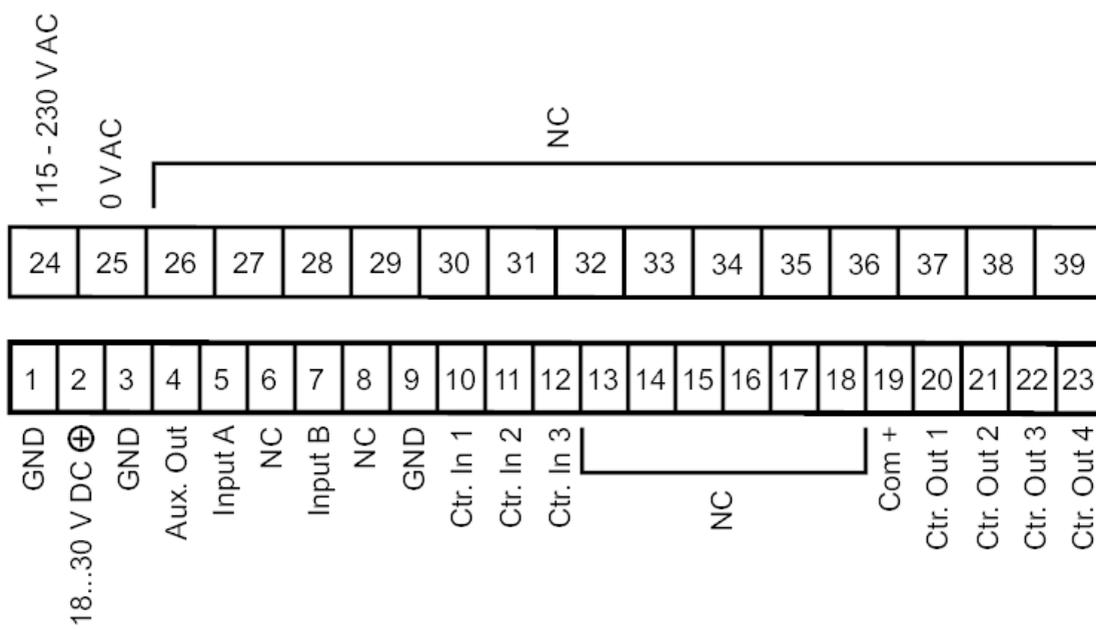

NC: not used