


53652

Tube Brush f/flexible handle  
53515 or 53525, 200 mm,  
Medium, Green

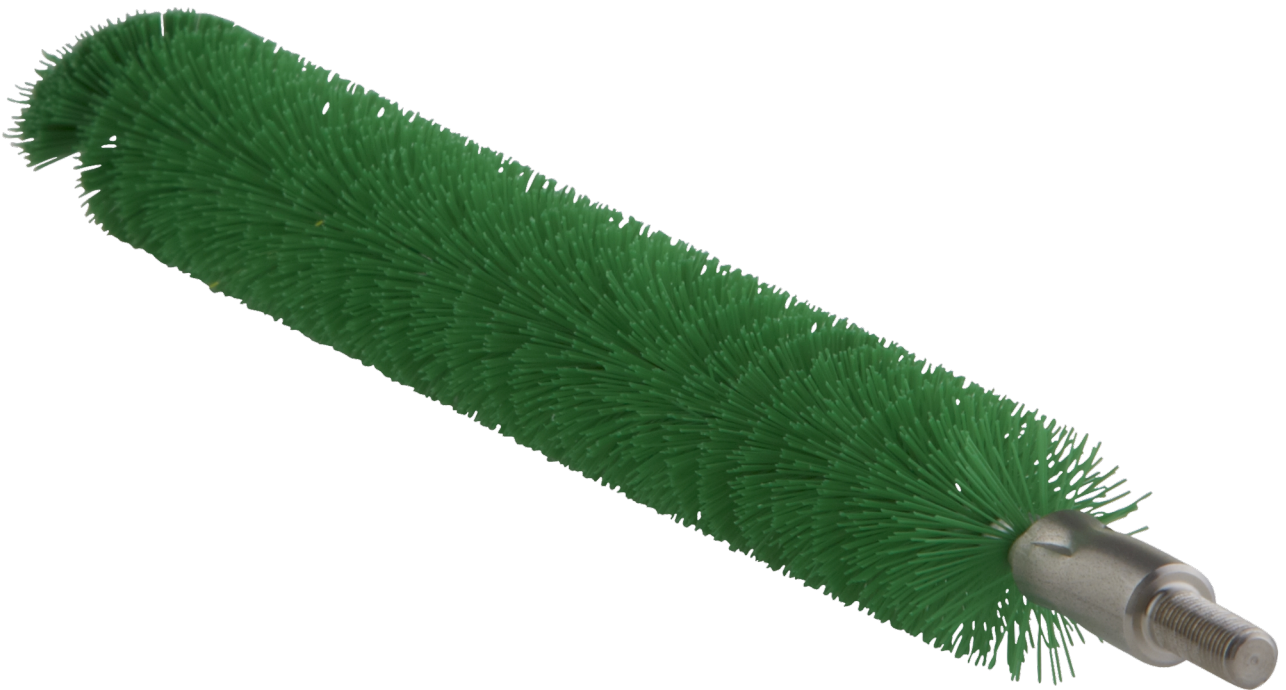

Brush for flexible handle, 53515 and 53525 Suitable for cleaning pipes in dairies, breweries and the fishing industry.

# Technical Data

Item Number	53652
Material	Polypropylene Polyester Stainless Steel
Suitable for Food Contact (EU 1935/2004), DoC <sup>1</sup>	Yes
Produced according to EU Regulation 2023/2006/EC of Good Manufacturing Practice	Yes
FDA compliant raw material (CFR 21)	Yes
Meets the REACH Regulation (EC) No. 1907/2006	Yes
Use of Phthalates (e.g. Bisphenol A)	No
Is Halal compliant	Yes
Box Quantity	10 Pcs.
Quantity per Pallet (80 x 120 x 200 cm)	5060 Pcs
Quantity Per Layer (Pallet)	0 Pcs.
Box Length	280 mm
Box Width	125 mm
Box Height	80 mm
Product Diameter	20 mm
Length	200 mm
Width	20 mm
Height	20 mm
Gross Weight	0,039 kg
Net Weight	0,03 kg
Cubik metre	0,0001 M3
Recommended sterilisation temperature (Autoclave)	121 °C
Max. cleaning temperature (Dishwasher)	93 °C
Max usage temperature (food contact)	80 °C
Max usage temperature (non food contact)	100 °C
Min. usage temperature	-20 °C
Min. pH-value in usage concentration	2 pH
Max. pH-value in Usage Concentration	10,5 pH
Gtin-13 Number	5705020536526
GTIN-14 Number (Box quantity)	15705020536523
Commodity Code	96039099
Country of origin	Denmark

New equipment should be cleaned, disinfected, sterilised and any labels removed, as appropriate to its intended use, e.g. high risk vs. low risk food production areas, general hospital areas vs. intensive care units, before use.

1. See Declaration of Compliance for further details on food contact