

FEATURES

- T8 Twin LED batten
- 3 hours switch maintained emergency
- Rate of Protection: IP20
- 30000 lifetime hours
- Metal body with White finish
- Non-Dimmable
- Lamp Type SMD LED
- Material Polycarbonate and Pressed Steel - metal body with white finish

LED Emergency Lighting Batten 50 W

RS Stock No.: 125-6919



RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

This RS PRO twin LED 3 hour switched maintained emergency batten is a great replacement for traditional T8 battens. Led lamp technology brings energy savings through lower power consumption and maintenance is reduced due to 30000 lifetime hours. Led lamp technology allows instant light at a colour temperature of cool white (4000K) with no warm-up time. This RS Pro LED batten is surface mounted and incorporates a polycarbonate diffuser to an IP20 rate of protection Options available:

- [125-6919](#) - 50W Twin Emergency Batten 5ft, 5250lm, Beam Angle 137
- [125-6921](#) - 60W Twin Emergency Batten 6ft, 6500lm, Beam Angle 134

General Specifications

| | |
|---------------------------|---|
| Lamp Type | LED |
| Light Style | Bulkhead |
| Luminosity | 5250lm |
| Colour Temperature | 4000K |
| Maintained | Maintained |
| Material | Steel + Polycarbonate |
| Finish | White |
| Duration | 3h |
| Lamp Supplied | Yes |
| Applications | Ideal for commercial, industrial and retail applications and can be found in: Corridors, Workshops, emergency exits, Carparks |

Electrical Specifications

| | |
|------------------------|---------|
| Wattage | 50W |
| Voltage Rating | 230V DC |
| Running Current | 0.245A |

Mechanical Specifications


| | |
|--------------|--------|
| Length | 1525mm |
| Width | 95mm |
| Depth | 85mm |
| Fitting Type | Batten |
| Weight | 2.86kg |

Protection Category

| | |
|-----------|------|
| IP Rating | IP20 |
|-----------|------|

Approvals

| | |
|-----------------------------|------|
| Compliance/Certifications | RoHS |
| EU Energy Efficiency Rating | A+ |

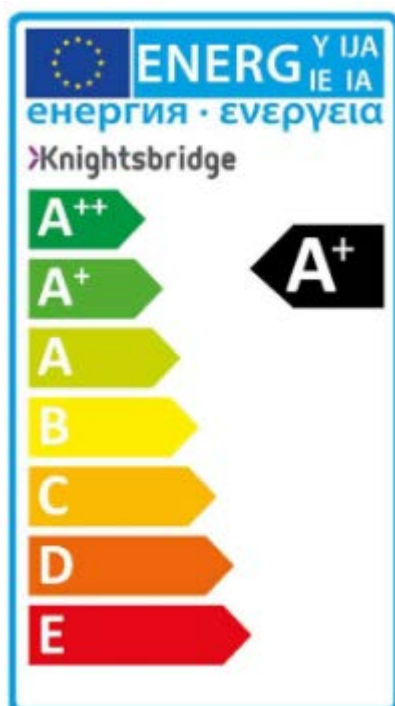

Ling Diagram:

