



Dimensions


Mounting hole with/without cut-out

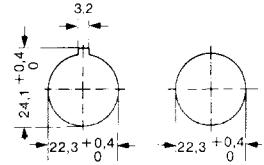

Grid dimensions to EN 50 007

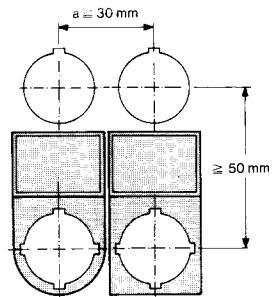

Minimum grid dimension

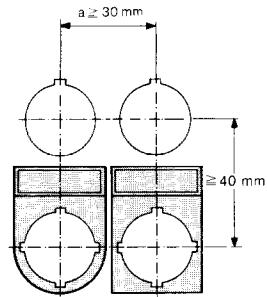


Minimum distance


RPV	33 mm
RP, MP	35 mm
RPSR, MPSR	35 mm
PL-RPV	48 mm

Front fixing


Push buttons

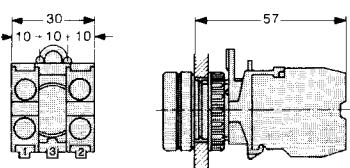


Indicator lamps/illuminated push-buttons

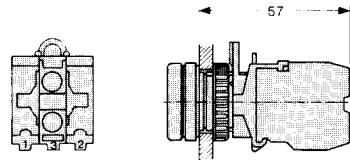


Indicator lamps/illuminated push-buttons with BFT... lamp transformer

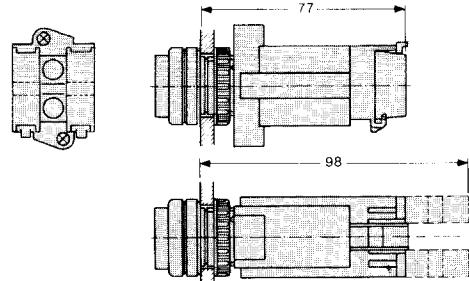


ET... lamp transformer for separate mounting, with blanking plug

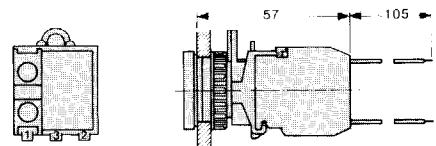

ER 6 resistor element for separate mounting, with blanking plug

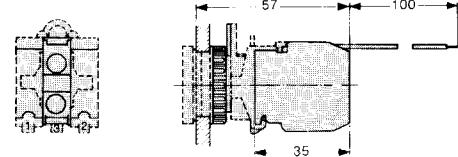


Fixing adapter

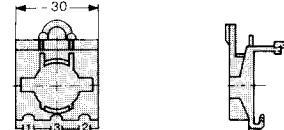


Base fixing


Push-buttons

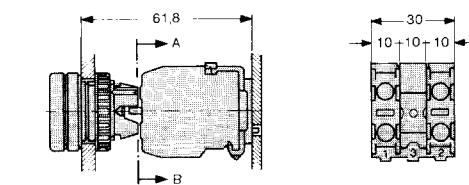


Indicator lamps/illuminated push-buttons

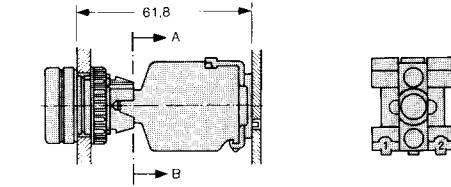


Indicator lamps/illuminated push-buttons with separate ET... lamp transformer

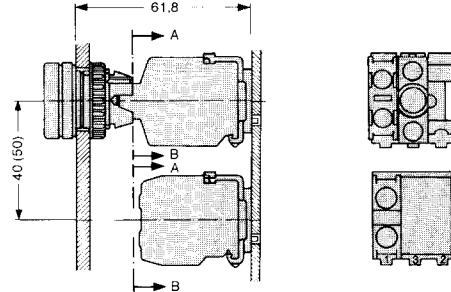


ET... lamp transformer for separate mounting, with blanking plug

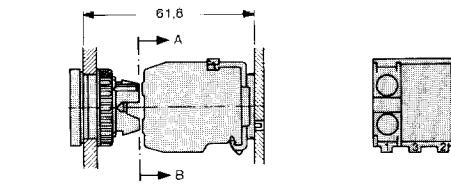

ER 6 resistor element for separate mounting

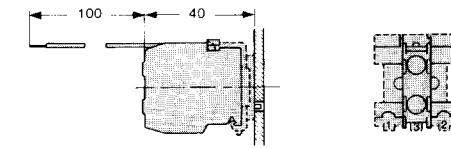

Fixing adapter

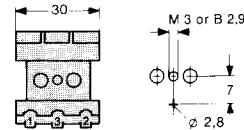

Push-buttons, illuminated push-buttons, indicator lamps with telescopic bracket for indirect rear mounting

