


KEMET Part Number: SSRH7H-M11081
(UALSH7M1108100)

KEMET, SSRH7H-M, AC Line Filters, Common Mode, 8100 uH

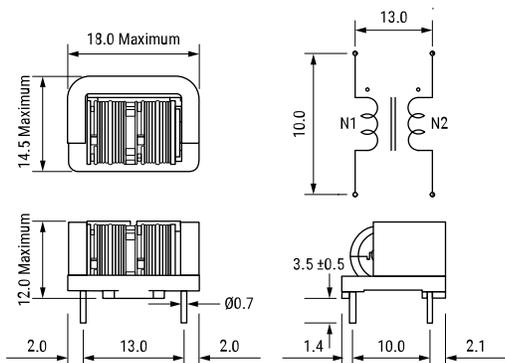

Dimensions

| | |
|-----------|----------------|
| L | 18mm MAX |
| T | 14.5mm MAX |
| H | 12mm MAX |
| LL | 3.5mm +/-0.5mm |
| S | 13mm NOM |

Packaging Specifications

| | |
|----------------------------|-------|
| Packaging: | Tray |
| Packaging Quantity: | 600 |
| Weight: | 5.2 g |

General Information

| | |
|-----------------------|--------------------------------|
| Series: | SSRH7H-M |
| Style: | Through-Hole |
| RoHS: | Yes |
| Notes: | M11 Lot No. |
| Miscellaneous: | Temperature Rise Maximum: 55 K |

Specifications

| | |
|---------------------------|-----------------|
| Voltage AC: | 250 VAC |
| Inductance: | 8.1 mH (10 kHz) |
| Current: | 1.1 A |
| Temperature Range: | -25/+120°C |
| DC Resistance: | 270 mOhms |