

SIVACON, swing frame, for the installation of 19" devices, load capacity up to 200 kg, H: 1800 mm, electrically zinc-plated

Model			
product brand name		SIVACON	
design of the product		For installation of 19" units, screwed	
design of the surface		Galvanized	
design of the product EMC version		No	
material		steel	
Appearance			
RAL color number		RAL 7035	
product component		No	
• ventilation			
Mechanical Design			
height		1 800 mm	
net weight		18 000 g	
Approvals Certificates			
General Product Approval		Test Certificates	other



[Special Test Certificate](#)

[Miscellaneous](#)

[Confirmation](#)

other	Environment
-------	-------------


[Miscellaneous](#)



[Environmental Confirmations](#)

Further information

Information on the packaging
<https://support.industry.siemens.com/cs/ww/en/view/109813875>
 Information- and Downloadcenter (Catalogs, Brochures,...)
<http://www.siemens.com/lowvoltage/catalogs>
 Industry Mall (Online ordering system)
<https://mall.industry.siemens.com/mall/en/en/Catalog/product?mlfb=8MF1800-2AR02-4>
 Service&Support (Manuals, Certificates, Characteristics, FAQs,...)
<https://support.industry.siemens.com/cs/ww/en/ps/8MF1800-2AR02-4>
 Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)
http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=8MF1800-2AR02-4
 CAx-Online-Generator
<http://www.siemens.com/cax>
 Tender specifications
<http://www.siemens.com/specifications>

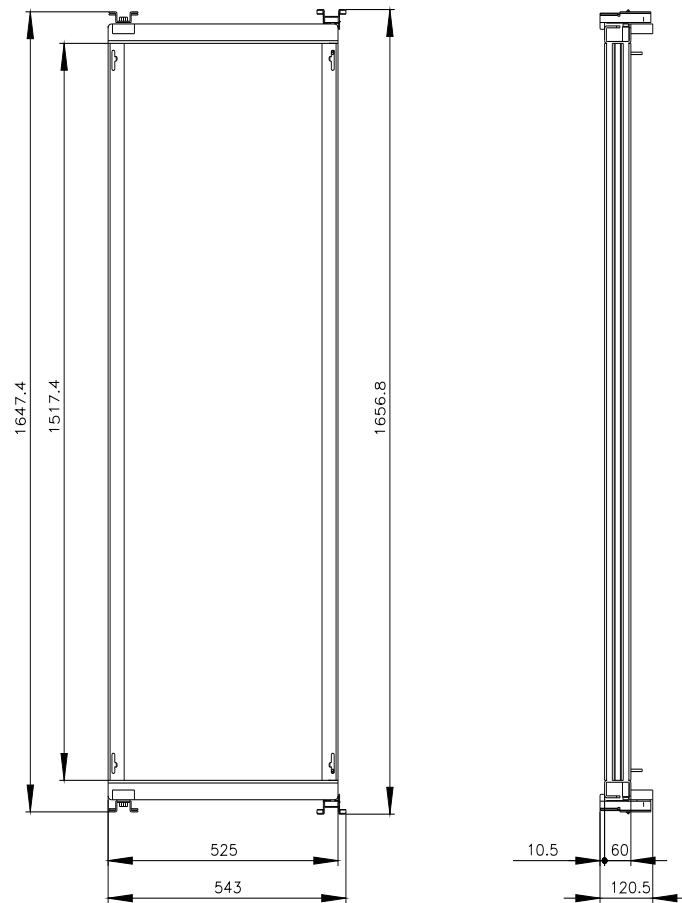

last modified:

4/13/2025 

