



DATASHEET



SUR5SLBK

230V IP20 40W LED Dual Mount Slim Line Luminaire
Matt Black

www.mlaccessories.co.uk

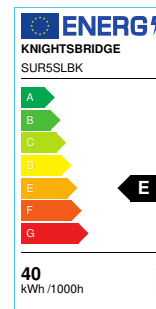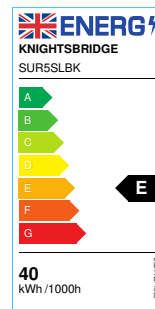

| MLA PART CODE | SUR5SLBK |
|-------------------------------|--|
| DESCRIPTION | 230V IP20 40W LED Dual Mount Slim Line Luminaire Matt Black |
| NET WEIGHT (KG) | 3.1 |
| FINISH | Matt Black |
| DIFFUSER | Opal |
| DIMENSIONS (MM) | Length - 1500 Width - 145 Projection - 45 |
| CONSTRUCTION | Construction - Pressed steel Construction 2 - & polypropylene |
| CLASS | I |
| IP RATING | IP20 |
| WATTAGE (W) | 40 |
| LAMP TECHNOLOGY | SMD LED |
| LAMP INCLUDED | Yes |
| LUMENS (LM) | 3010 |
| LUMENS LIGHT SOURCE ONLY (LM) | 5320 |
| LUMEN TOLERANCE | 5% |
| EFFICACY (LM/W) | 133 |
| CIRCUIT WATTAGE (W) | 40 |
| CCT | 4000K |
| LIGHT COLOUR | Cool White |
| CRI | >80 |
| SDCM | <6 |
| RUNNING CURRENT (A) | 0.18 |
| DISPLACEMENT FACTOR | >0.9 |
| SVM | 0 |
| PST-LM | 0 |
| BEAM ANGLE (DEGREES) | 115 |
| L70B50 LIFESPAN (HRS) | 50,000 |

| | |
|--|---|
| DIMMABLE | No |
| OPERATING TEMPERATURE | 25°C |
| INPUT VOLTAGE | 230V 50Hz |
| CABLE ENTRY (MM) | 20 |
| CABLE GLAND INCLUDED | Blind grommet |
| DRIVER | DRIVER TYPE - Constant Current MAX. OUTPUT - 42W OUTPUT VOLTAGE - 30-43V OUTPUT CURRENT - 960mA POWER FACTOR - 0.95 EFFICIENCY FULL LOAD - 95.0 ISOLATION - SELV AMBIENT TEMPERATURE (Ta) - -20~50°C CASE TEMPERATURE (Tc) - 75°C |
| WARRANTY | 5year(s) |
| MANUFACTURED IN ACCORDANCE WITH | BS 60598 |
| ORIGIN OF MANUFACTURE | China |
| DECLARATION OF CONFORMITY (HELD ON FILE) | Yes |
| EAN | 5061061275276 |

Date Created: 26/06/2025 11:10

