




### TAH08-PH

## 1/4" Square Drive Socket Drivers for Phillips Head Screws with 4 Points Solution



### PRODUCT DETAILS

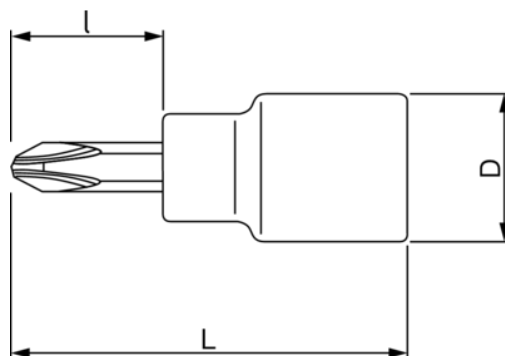

- Not suitable for machine operation
- Knurled area for better grip
- Highly polished finish
- High-performance alloy steel
- Standards: ISO 1174, DIN 3120
- Suitable for working at height
- 4 side lock holes ensure positive retention and full functionality
- Colour plate with maximum weight to match with lanyard
- According to DROPS best practices



Follow the Fish!



PRODUCT ATTRIBUTES

Product		<b>I</b>	<b>L</b>	<b>D</b>	
<b>TAH08-PH1</b>	1	16 mm	36 mm	12 mm	11 g
<b>TAH08-PH2</b>	2	16 mm	36 mm	12 mm	20 g
<b>TAH08-PH3</b>	3	16 mm	36 mm	12 mm	12 g

