


FEATURES

- **Non-Releaseable Design:** Ensures a secure and permanent fastening solution.
- **Nylon Material:** Offers durability and resistance to wear and tear.
- **UL 94 V-0 Fire Behaviour:** Provides excellent flame retardancy for enhanced safety.
- **Tensile Strength of 8 kg:** Capable of holding cables firmly in place.
- **Maximum Bundle Diameter of 55 mm:** Suitable for a wide range of cable sizes.
- **RoHS Compliant:** Meets environmental and safety standards.

RS PRO 203mm Nylon Cable Tie, Non-Releaseable

RS Stock No: 656-036

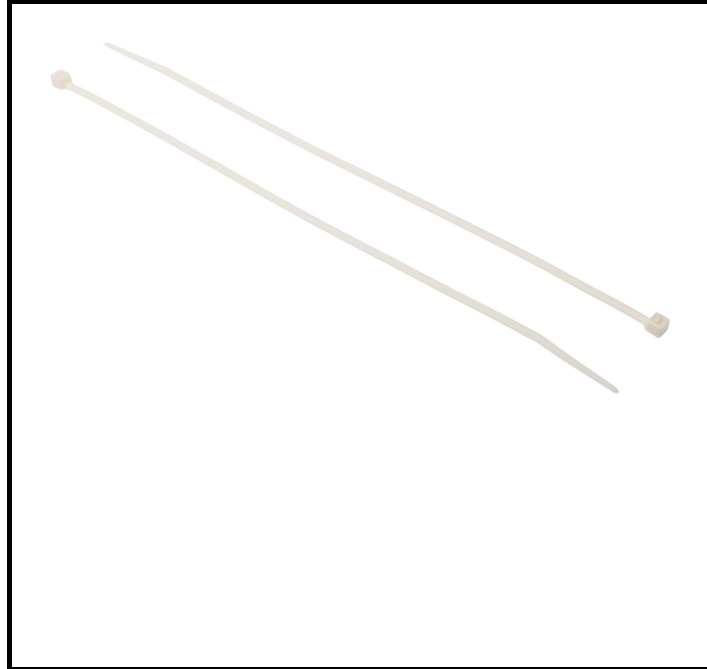

RS Professionally Approved Products bring to you professional quality parts across all product categories. Our product range has been tested by engineers and provides a comparable quality to the leading brands without paying a premium price.

Product Description

RS PRO offers a reliable and durable solution for cable management with its 203mm Nylon Cable Tie. Designed for securing and organising cables, this non-releasable cable tie is ideal for both industrial and domestic applications, providing a strong and secure hold.

General Specifications

Colour	White
Product Type	Cable Tie
Sub Type	Non-Releasable
Tensile Strength	8 kg

Protection Category

Fire Behaviour	UL 94 V-0
UV Resistant	No

Mechanical Specifications

Length	203 mm
Material	Nylon
Maximum Bundle Diameter	55 mm
Width	2.5 mm

Operation Environment Specifications

Maximum Operating Temperature	85 °C
-------------------------------	-------

Approvals

Standards/Approvals	RoHS, UL94V-0
---------------------	---------------

