




CDM-T are single-ended metal halide lamps with a warm colour impression (3000 K) and excellent colour rendering, plus stable colour characteristics over lifetime. The small axial discharge arc and compact lamp dimensions allow high beam intensities to be created. The prefocused lamp position in the luminaire minimises spill light. CDM-T lamps require a ballast and ignitor or a full electronic ballast like the Philips EMC.

The relatively low heat output enhances comfort in indoor applications.  
Burning position: universal.

### Applications

- Shop window display lighting
- Offices and public buildings
- Floodlighting
- Pedestrian areas

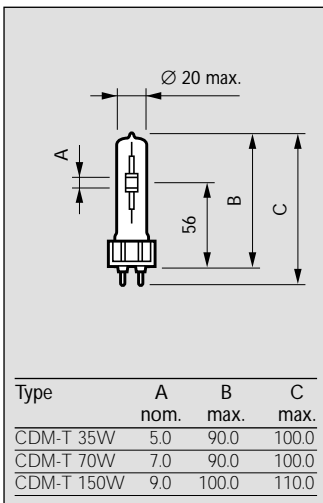

Dimensions in mm

Type	Lumen output lm	Correlated colour temperature K	Ordering number
CDM-T 35W /830 G12	3400	3000	9280 831 05100
CDM-T 70W /830 G12	6400	3000	9280 823 05100
CDM-T 150W /830 G12	14000	3000	9280 837 05100

