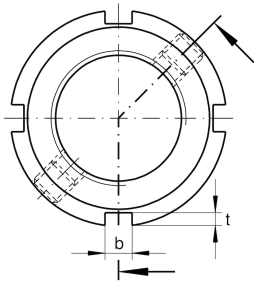
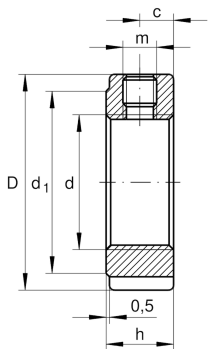
**ZM110** **Precision locknut**

Precision locknut ZM, accessory ZM..

Technical information**Main Dimensions & Performance Data**

d	M110X2	Thread
D	145 mm	Outside diameter
h	22 mm	Height
M _A	20 Nm	Mounting torque set screw
F _{aB}	520,000 N	Breaking load, axial
M _L	510 Nm	Breakawag
M _{AL}	350 Nm	Mounting torque reference
M _M	50.1 kg*cm ²	Mass moment of inertia
≈m	1.166 kg	Weight

Dimensions

d ₁	133 mm	Plant diameter outside
t	5 mm	Hight retaining slot
b	12 mm	Width retaining slot
c	11 mm	Distance bore
m	M10	Threaded - threaded pin