

Product data sheet

Specifications



Harmony XVC, Monolithic precabled tower light, plastic, red orange green, Ø60, base mounting, steady or flashing, buzzer, IP54, 24 V AC/DC

XVC6B35SK

Main

Range of product	Harmony XVC6
Product or component type	Complete pre-wired monolithic tower light
Beacon or indicator bank unit type	3 illuminated units
Sound signalling	Buzzer
Mounting diameter	60 mm
Component name	XVC
Light source	LED steady or flashing red LED steady or flashing orange LED steady or flashing green
[Us] rated supply voltage	24 V
Supply circuit type	AC/DC
Noise level	70...85 dB (continuous or intermittent tone) at 1 m

Complementary

Material	Polycarbonate: illuminated unit ABS (acrylonitrile butadiene-styrene): base unit PBT + ABS (UL94HB): top cover
Product mounting	On base
Cable cross section	0.33 mm²
AWG gauge	AWG 22
Cable length	850 mm
Marking	CE
[Uimp] rated impulse withstand voltage	0.8 kV
Current consumption	115 mA
Fundamental frequency	2.23 kHz
Flashing frequency	1 Hz
Net weight	0.3 kg
Height	200.8 mm

Environment

Standards	EN/IEC 61000-6-4 EN/IEC 61000-6-3 EN/IEC 61000-6-2
Product certifications	UL
Protective treatment	TC
Ambient air temperature for storage	-35...70 °C
Ambient air temperature for operation	-10...50 °C
Electrical shock protection class	Class II conforming to EN/IEC 61140
IP degree of protection	IP54 flat surface installation conforming to EN/IEC 60529

Packing Units

Unit Type of Package 1	PCE
Number of Units in Package 1	1
Package 1 Height	8.8 cm
Package 1 Width	8.5 cm
Package 1 Length	50.5 cm
Package 1 Weight	533.0 g
Unit Type of Package 2	S04
Number of Units in Package 2	10
Package 2 Height	30.0 cm
Package 2 Width	40.0 cm
Package 2 Length	60.0 cm
Package 2 Weight	6.572 kg

Offer Sustainability

EU RoHS Directive	Pro-active compliance (Product out of EU RoHS legal scope) EU RoHS Declaration
Mercury free	Yes
China RoHS Regulation	China RoHS declaration
RoHS exemption information	Yes
Environmental Disclosure	Product Environmental Profile
Circularity Profile	End of Life Information
California proposition 65	WARNING: This product can expose you to chemicals including: Lead and lead compounds, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information go to www.P65Warnings.ca.gov


Contractual warranty

Warranty	18 months
----------	-----------

Pre-assembled and Pre-wired Tower Light

Dimensions

Below drawing shows the maximum configuration of the product. Select the number of stages according to the product characteristics in order to get **b** dimension.

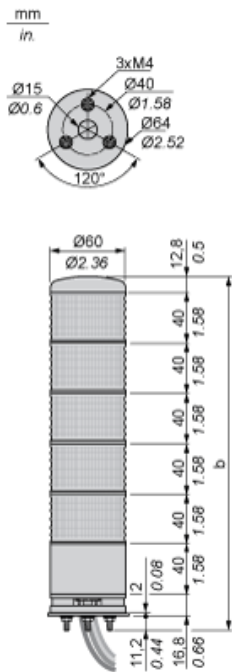


No. of illuminated units	b (mm)	b (in.)
1 stage	120.8	4.76
2 stages	160.8	6.33
3 stages	200.8	7.90
4 stages	240.8	9.48
5 stages	280.8	11.06

Pre-assembled and Pre-wired Tower Light

Mounting on Horizontal Support (Direct or with Fixing Plate)

Panel cut-out

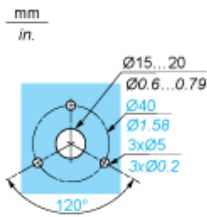

Recommended replacement(s)