




## DISCOVER 3 professional display

### DIS-5520 UK

- Legamaster DISCOVER range of professional displays offers a cost-efficient solution to upgrade presentations in both corporate and educational settings
- Available from 43 to 98 inch, the DISCOVER displays are made especially for medium to big meeting-spaces or classrooms
- Onboard, users can find a web-browser, media player and office document player that offer basic functionality without any connected devices needed
- A basic and local narrow casting app is pre-installed on the device providing a basic public information display functionality but it also has a central management content display integration App using an external service solution providing a scalable control of the displayed content
- An integrated tiling tool will provide support for a up to 5x5 video wall solution without the need of purchasing any additional hardware
- Flexible usage options: without Android, with only a launcher for fast and intuitive ways to switch to peripheral device, or in full Android mode, offering easy source switching and also a host of applications, including an appstore for even more functionality


Art.No. **7-805120-55-UK**

GTIN **8713797116169**

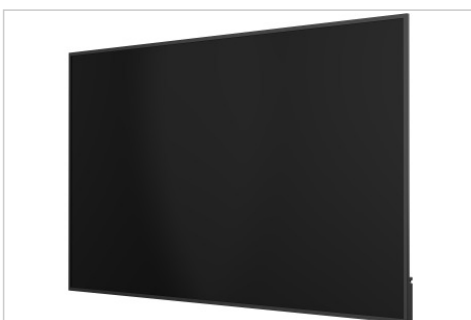

## Highlights

- Free OTA updates
- Landscape/portrait support
- Haze level 25%
- Integrated video wall tool for up to 5x5
- Integrated rotation sensor
- Pre-installed casting solution
- Android 14
- USB-C (up to 65W + DP 1.2)
- 1x HDMI output
- 3x HDMI input

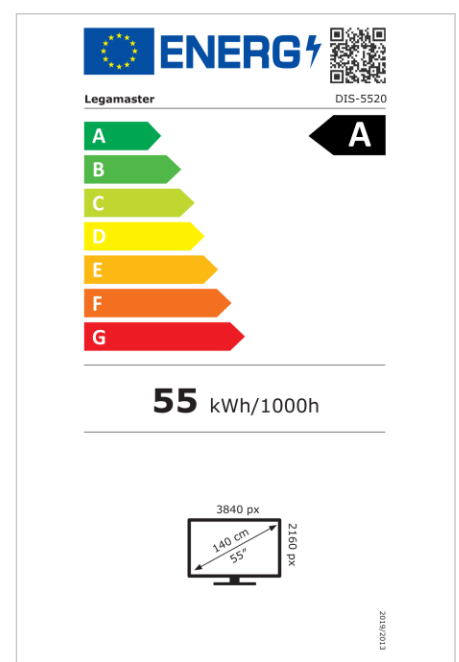

# Article data sheet

## DISCOVER 3 professional display DIS-5520 UK

### Display

- Display diagonal: 55 inch
- Display technology: LED
- Panel type: VA
- Backlight type: Direct LED
- Display resolution: 3840 x 2160 px | 4K Ultra HD
- Display brightness: 500 cd/m<sup>2</sup>
- Display number of colours: 1.073 billion colours
- Contrast ratio (static): 5000:1
- Contrast ratio (dynamic): 5000:1
- Aspect ratio: 16:9
- Display refresh rate: 60 fps
- Response time: 6.5 ms
- Viewing angle: H: 178° / V: 178°
- Display control: IR remote controller, Ethernet, RS-232C
- Lifespan: 50000 hours
- Durability: 24/7
- Screen orientation: Landscape, Portrait

### Glass

- Glass surface treatment: Anti-glare
- Glass bonding type: None

### Ports & Interfaces

- HDMI input ports: 3x 2.0 Type-A
- HDMI output ports: 1x 2.0 Type-A
- USB ports: 1x USB 2.0 Type-A, 1x USB 3.0 Type-A, 1x USB 2.0 Type-C (DP1.2 | up to 65W)
- Ethernet ports: 1x RJ-45
- Audio input ports: 1x Jack 3.5 mm
- Audio output ports: 1x Jack 3.5 mm, 1x Mini-TOSLINK (S/PDIF)
- Serial port type: RS-232

### System

- CPU: Arm Cortex-A73x4
- Graphics: Arm Mali-M57 MC1
- Memory size: 4 GB
- Storage size: 32 GB
- Operating system: Android 14 (upgradable)

### Audio & Video

- Built-in camera: No
- Built-in microphone: No
- Built-in speakers: Yes
- Number of speakers: 2
- Speaker specifications: 2x16W

### Network

- Ethernet standards: 10BASE-T, 100BASE-T, 1000BASE-T
- Wi-Fi standards: Wi-Fi 6E (802.11ax)
- Bluetooth version: 5.3
- Access point capability: Yes

### Power

- Power supply: AC | 100 - 240 V | 50/60 Hz
- Power consumption (sleep mode): 0.5 W
- Power consumption (standby): 0.5 W
- Energy efficiency scale: A to G

### Operational conditions

- Operating relative humidity: 10 % - 90 %
- Storage relative humidity: 10 % - 90 %
- Operating temperature: 0 °C - 40 °C
- Storage temperature: -20 °C - 60 °C

### Mounting

- VESA mounting interface: 400 x 400
- Suitable screw: M6

### Dimensions & Logistics

- Dimensions of product (W x H x D): 1233 x 703.5 x 62 mm
- Dimensions of package carton (W x H x D): 156 x 839 x 1332 mm
- Gross weight: 18.32 kg
- Net weight: 13.28 kg
- Bezel width: 9.9 mm
- Customs tariff number: 852852100000

### Packaging data

- Package contents: Remote control unit, Power cable 3.2m, Wi-Fi module

### Warranty

- Product warranty: 5 years

## Article data sheet

### Product overview

| Article name                                                  | Article number        | GTIN/EAN             | Minimum order quantity |
|---------------------------------------------------------------|-----------------------|----------------------|------------------------|
| Legamaster DISCOVER 3 professional display DIS-4320 AR        | 7-805120-43-AR        | 8713797116190        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-4320 CH        | 7-805120-43-CH        | 8713797116114        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-4320 EU        | 7-805120-43-EU        | 8713797116183        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-4320 UK        | 7-805120-43-UK        | 8713797116206        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-4320 US        | 7-805120-43-US        | 8713797116213        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-5520 AR        | 7-805120-55-AR        | 8713797116145        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-5520 CH        | 7-805120-55-CH        | 8713797116152        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-5520 EU        | 7-805120-55-EU        | 8713797116138        | 1                      |
| <b>Legamaster DISCOVER 3 professional display DIS-5520 UK</b> | <b>7-805120-55-UK</b> | <b>8713797116169</b> | <b>1</b>               |
| Legamaster DISCOVER 3 professional display DIS-5520 US        | 7-805120-55-US        | 8713797116176        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-6520 AR        | 7-805120-65-AR        | 8713797116084        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-6520 CH        | 7-805120-65-CH        | 8713797116091        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-6520 EU        | 7-805120-65-EU        | 8713797116077        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-6520 UK        | 7-805120-65-UK        | 8713797116107        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-6520 US        | 7-805120-65-US        | 8713797116121        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-7520 AR        | 7-805120-75-AR        | 8713797116039        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-7520 CH        | 7-805120-75-CH        | 8713797116046        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-7520 EU        | 7-805120-75-EU        | 8713797116022        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-7520 UK        | 7-805120-75-UK        | 8713797116053        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-7520 US        | 7-805120-75-US        | 8713797116060        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-8620 AR        | 7-805120-86-AR        | 8713797115988        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-8620 CH        | 7-805120-86-CH        | 8713797115995        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-8620 EU        | 7-805120-86-EU        | 8713797115971        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-8620 UK        | 7-805120-86-UK        | 8713797116008        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-8620 US        | 7-805120-86-US        | 8713797116015        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-9820 AR        | 7-805120-98-AR        | 8713797115933        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-9820 CH        | 7-805120-98-CH        | 8713797115940        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-9820 EU        | 7-805120-98-EU        | 8713797115926        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-9820 UK        | 7-805120-98-UK        | 8713797115957        | 1                      |
| Legamaster DISCOVER 3 professional display DIS-9820 US        | 7-805120-98-US        | 8713797115964        | 1                      |