


Ex-Level Gauge Light Fitting eLLK 92 with Electronic Ballast

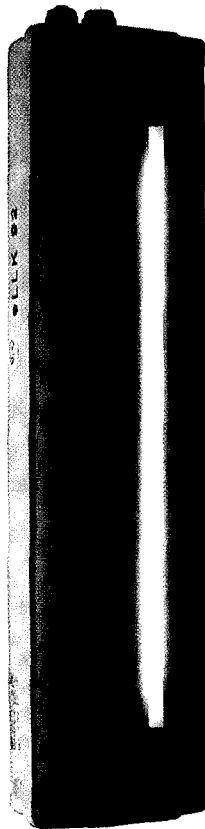

eLLK 92018/18 (2 x 18 W)
eLLK 92036 (1 x 36 W)

Technical data

eLLK 92 for bi-pin fluorescent lamps

Explosion category	Ex eds IIC T4 for zone 1
EC-Type Examination Certificate	PTB 96 ATEX 2144
Enclosure material	Glass-mat reinforced polyester
Protective bowl	Polycarbonate
Rated voltage	110 - 254 V AC $\pm 10\%$; 47 - 63 Hz 110 - 230 V DC $\pm 10\%$
Protection category	IP 66 acc. to EN 60529 (corr. to IEC 529)
Insulation class	I
Permissible ambient temperatures	-25°C to +50°C
Cable entries	M25 x 1.5 for cables $\varnothing 8 - 17$ mm
Terminals	L1, L2, L3, L, N, PE; max. 2 x 6 mm ² solid conductor per terminal
Illuminants	Bi-pin lamp: 18 W (G13-81-IEC-1105-1) 36 W (G13-81-IEC-1305-2)
Light emission, level gauge light fittings	630 mm (2 x 18 W) 1240 mm (1 x 36 W)
Weight	4.6 kg (2 x 18 W) 6.7 kg (1 x 36 W)

Ordering details

Type	Lamp	Circuitry	Order No.
eLLK 92018/18 P2 1/6-1	2 x 18 W	EVG	1 2265 875 126
eLLK 92036 P3 1/6-1	1 x 36 W	EVG	1 2263 875 125


1/6-1

Single-ended through-wiring

- 1 x M25 x 1.5 plastic cable gland with stopping plug
- 1 x M25 x 1.5 plastic cable gland with dust screen

Light emission of protective bowls

Version	A mm	B mm
P 2	630	50
P 3	1240	44

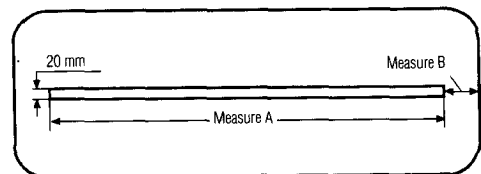

Dimensions in mm

	X	Y	Z
18 W	400	760	732
36 W	700	1,360	1,332

