



Technical data

NA2205LL/3AS

Roller follower with inner ring

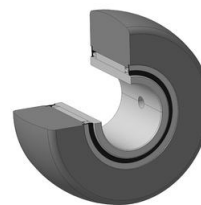

VISUAL (S)

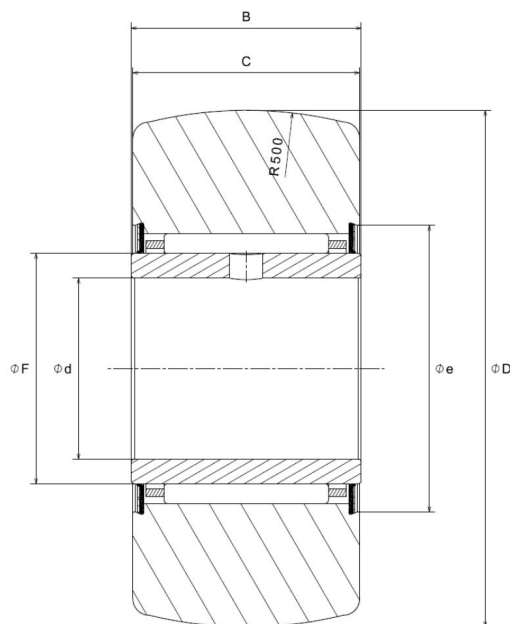

PRODUCT DEFINITION

Brand	NTN
d - Internal diameter	25 mm
D - External diameter	52 mm
C - Width of bearing, drawn cup or outer ring	17,8 mm
F - Under roller diameter	30 mm
B - Bearing/Inner ring width	18 mm
e - Inlet diameter of roller or washer	38 mm
R - Track roller radius	500 mm
rs - Min fillet radius	0,3 mm



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
 S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
 SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15

NA2205LL/3AS

Roller follower with inner ring

PRODUCT DEFINITION

Bearing with/without cage	Avec
Radial clearance class	CN
Precision class	P0
Mass	0,209 kg

PRODUCT PERFORMANCE

Cr - Dynamic load rating	17,9 kN
C0r - Static load rating	25,9 kN
Track load capacity spherical outer ring	5,55 kN
N lim - Grease lubrication limit speed	5000 tr/min
Tmin - Min operating temperature	-20 °C
Tmax - Max operating temperature	100 °C

ESHOPDONOTDISPLAY

Tracepart	Oui/Yes
Reference	NA2205LL/3AS
Image	NRBNA22_LL_1.jpg, NRBNA22_LL_3.jpg
Rolling element material	Acier 100Cr6



NTN Europe

1 rue des Usines · BP 2017 · 74010 Annecy Cedex · France · Tel. +33 (0)4 50 65 30 00
S.A. au capital de 322 639 919 € · RCS ANNECY B 325 821 072 · Id. Fiscale : FR 48 325 821 072
SIRET 325 821 072 00015 · Code APE 2815 Z · Code NACE 28.15