


# push-in Y-connector NPQM-Y-Q6-Q4-P10

Part number: 558803

FESTO

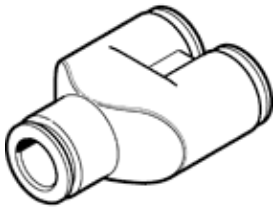

## Data sheet

Feature	Value
Size	Standard
Nominal size	3.5 mm
Design structure	Push/pull principle
Operating pressure complete temperature range	-0.95 ... 16 bar
Operating medium	Compressed air in accordance with ISO8573-1:2010 [7::-:]
Note on operating and pilot medium	Lubricated operation possible
Corrosion resistance classification CRC	1 - Low corrosion stress
Ambient temperature	-20 ... 70 °C
Product weight	35.9 g
Pneumatic connection, port 1	For tubing outside diameter 6 mm
Pneumatic connection, port 2	For tubing outside diameter 4 mm
Materials note	Conforms to RoHS
Material housing	Nickel-plated brass
Material of tubing seal	NBR